
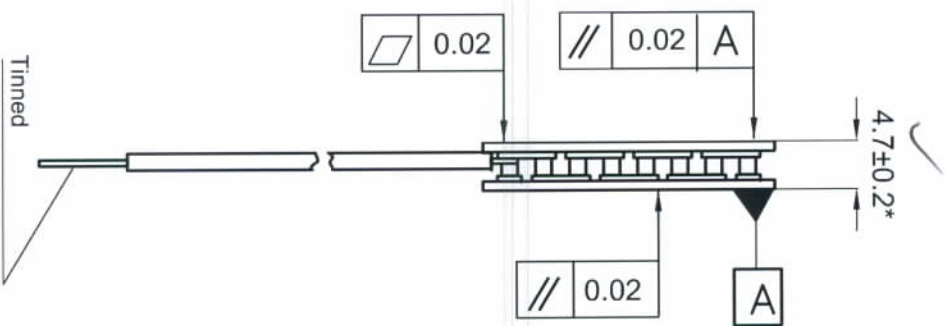


First two digits is a spec. code

The rest is a lot #

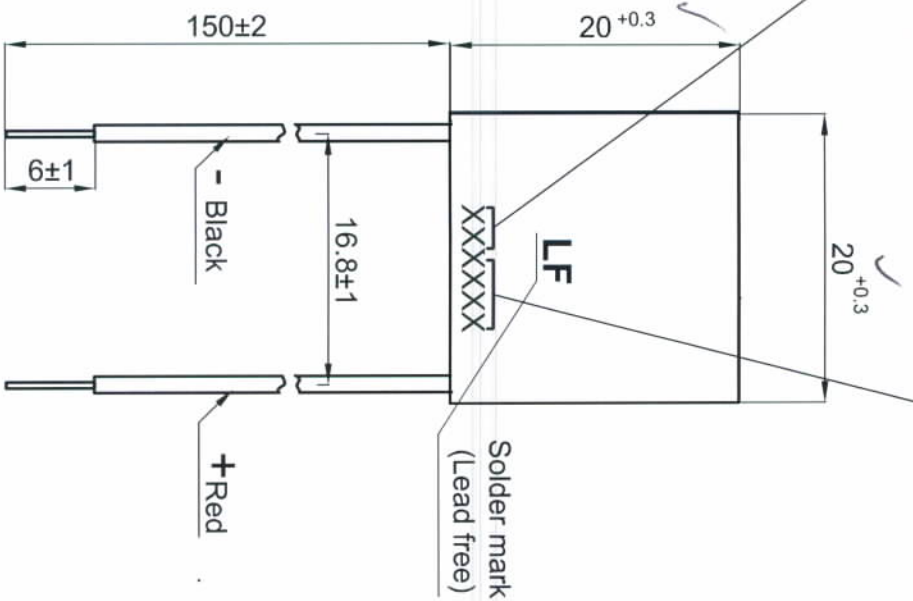

Technical Data	
V max	3.8 V ✓
Q max	8.5 W ✓
ΔT max	73° ✓
I max	3.7 A ✓
R	0.75 Ohm
Lead wires	20 AWG (0.5mm <sup>2</sup> ) PVC insulation (+90°C)
Sealing	No Sealing ✓
Solder	Lead Free ✓
Ceramics	Al <sub>2</sub> O <sub>3</sub> , white 96%
Maximum processing temperature	170°C
Tolerances for thermal and electrical parameters ±10%	
*Close height tolerance ±0.02 -upon request	

Thermoelectric module  
QC -31-1.4-3.7 M

Drawing № ND 037.00.00 C-2