


First two digits is a spec. code

The rest is a lot #

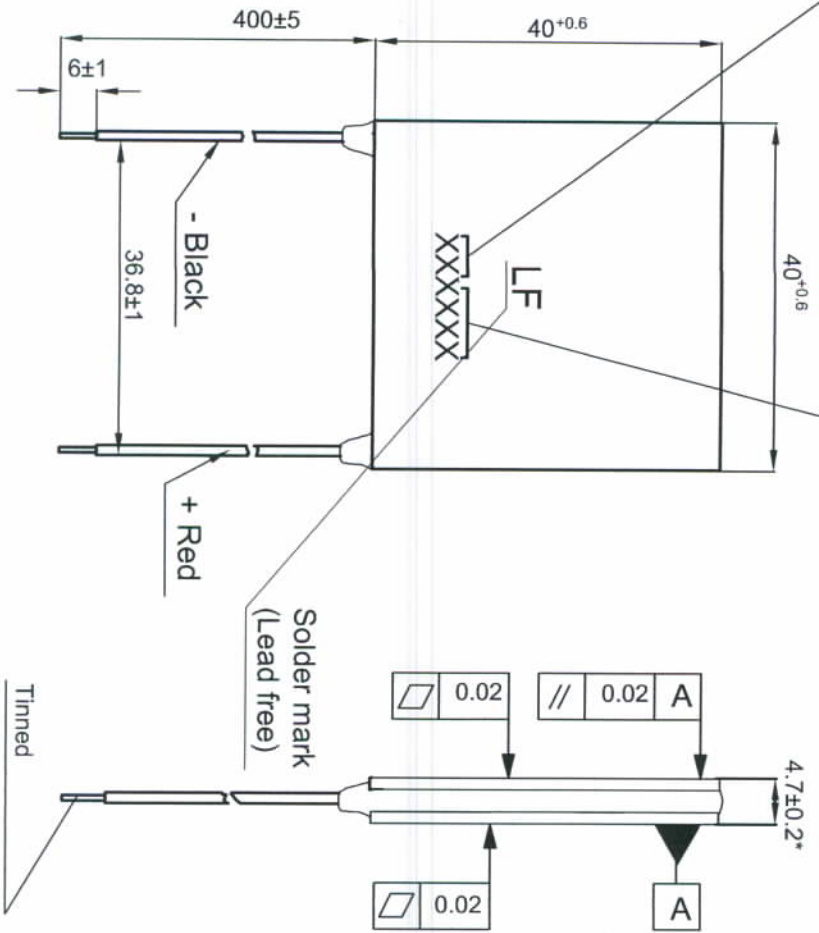

Technical Data	
V max	15.5 V
Q max	33.8 W
ΔT max	69°
I max	3.7 A
R	3.1 Ohm
Lead wires	20 AWG (0.5mm ²) PVC insulation (+90°C)
Sealing	Silicon Sealant
Solder	Lead Free
Ceramics	Al ₂ O ₃ , white 96%
Tolerances for thermal and electrical parameters ±10%	
Maximum processing temperature 200°C	
*Close height tolerance ±0.02 -upon request	

T_{hot}=27°C
vacuum

Thermoelectric module

QC -127-1.4-3.7 MS

Drawing No ND 012.00.00 C-19