



First two digits is a spec. code

The rest is a lot #

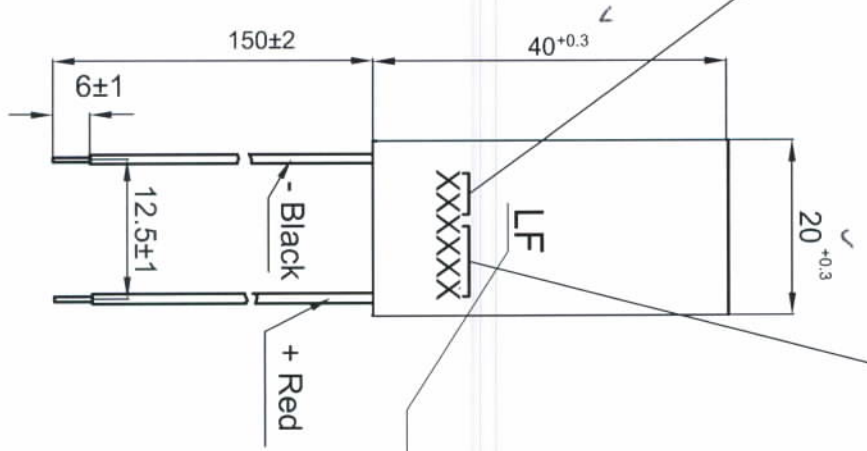

Solder mark (Lead free)

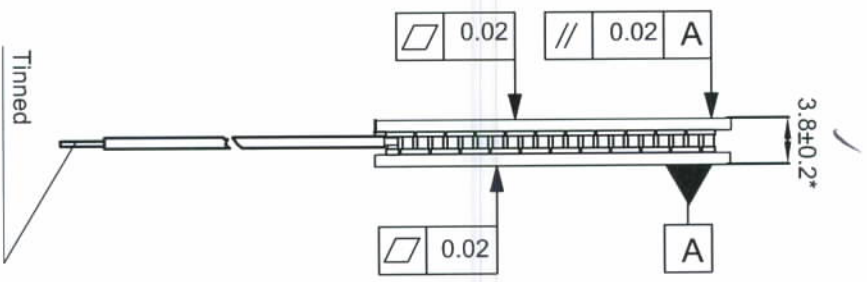

Technical Data

V max	7.7 V	✓
Q max	26.0 W	✓
ΔT max	71°	✓
I max	6.0 A	✓
R	1.05 Ohm	

$T_{hot} = 25^\circ C$
Dry air

Lead wires

20 AWG (0.5mm²)
Teflon insulation (+200°C)

Sealing	No Sealing	✓
Solder	Lead Free	✓

Ceramics Al₂O₃, white 96%

Maximum processing temperature +170°C

Tolerances for thermal and electrical parameters ±10%

*Close height tolerance ±0.02 -upon request

Thermoelectric module

QC -63-1.4-6.0 M

Drawing № ND 006.00.00 C-5