
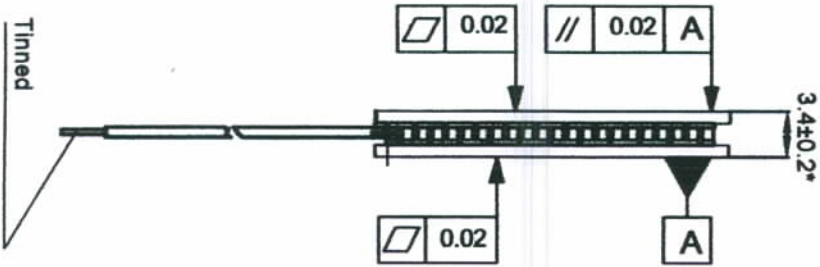


First two digits is a spec. code

The rest is a lot #

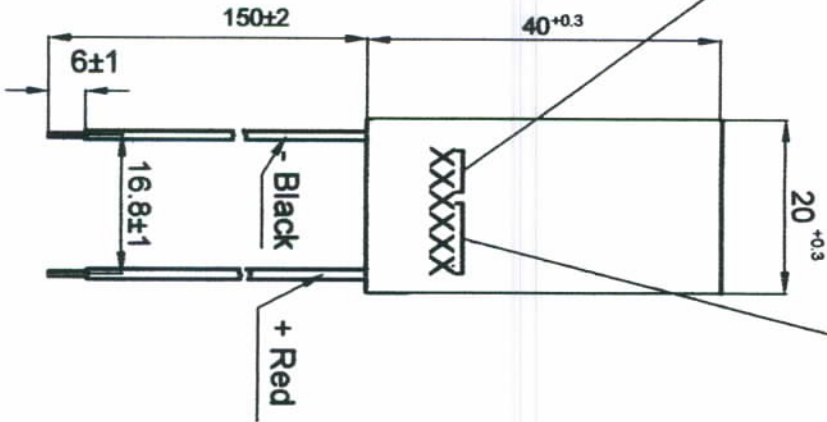

Technical Data	
V max	7.6 V
Q max	33.0 W
ΔT max	70°
I max	8.5 A
R	0.74 Ohm
Lead wires	20 AWG (0.5mm <sup>2</sup> ) PVC insulation (+90°C)
Sealing	No Sealing
Solder	Lead Free
Ceramics	Al <sub>2</sub> O <sub>3</sub> , white 96%
Maximum processing temperature	200°C
Tolerances for thermal and electrical parameters ±10%	
*Close height tolerance ±0.02 -upon request	

T<sub>hot</sub>=27°C  
vacuum

Thermoelectric module

QC -63-1.4-8.5 M

Drawing № ND 055.00.00 C-2