


First two digits is a spec. code

The rest is a lot #

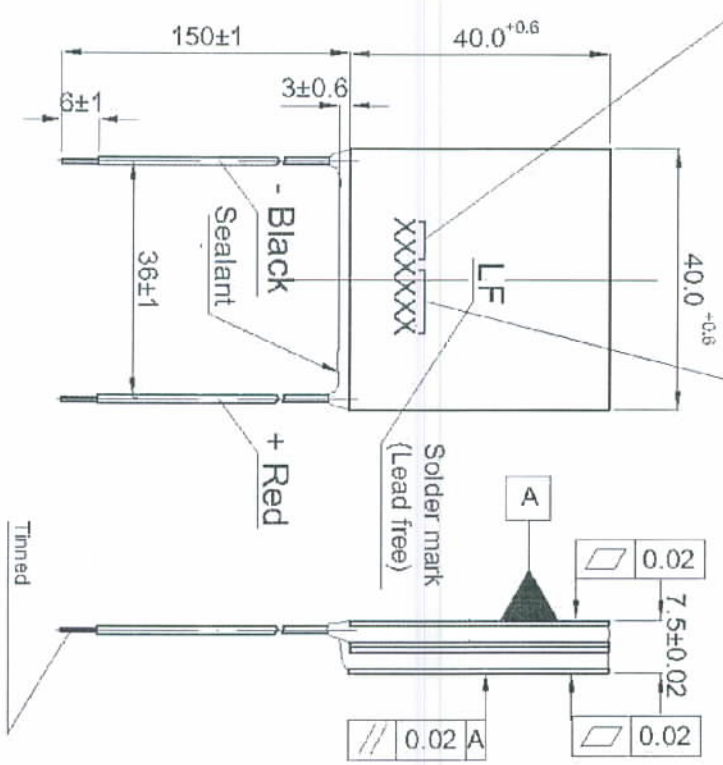

Technical Data

V max	16.0 V	T _{hot} =27°C vacuum
Q max	35.0 W	
ΔT max	82°	
I max	6.5 A	
R	2.1 Ohm	

Lead wires

20 AWG (0.5mm²)
PVC insulation (+90°C)

Sealing

Silicon Sealant

Solder

Lead Free

Ceramics Al₂O₃, white 96%

Maximum processing temperature +200°C

Tolerances for thermal and electrical parameters ±10%

Thermoelectric module

2QC-127-63-6.5 MS