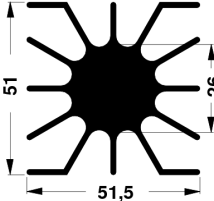
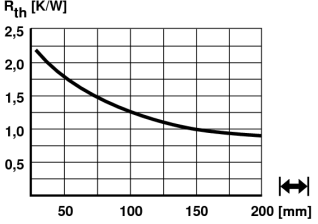
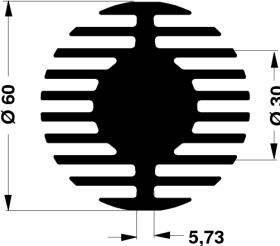
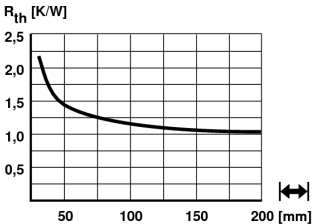
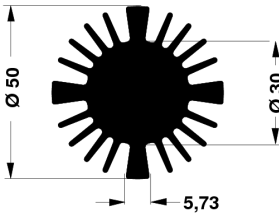
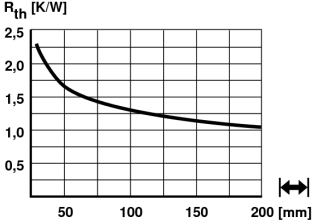
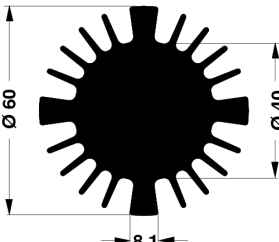
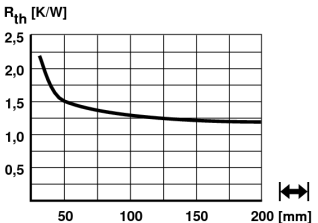
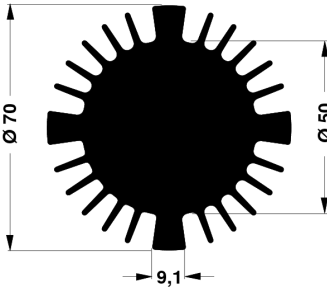
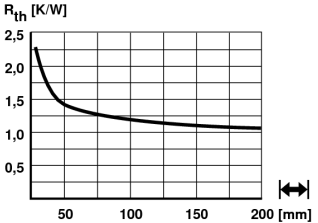



Heatsinks for LEDs

art. no. SK 46 ...		
art. no. SK 578 ...		
art. no. SK 577 ...		
art. no. SK 569 ...		
art. no. SK 570 ...		
please indicate: ...  10 15 20 25 37.5 50 1000 mm		

special design, surfaces and modification to customer specification on request
surface: black anodised

Pin heatsinks Ø
 Heatsinks for LED Ø
 Special heatsink design
 Thermal conductive paste

→ B 26 - 28 Thermal conduct. foil WLFT 404/405
 → B 29 - 33 Thermally conductive material
 → A 135 - 136 SMD-heatsinks
 → E 13 Technical annotations

→ E 5
 → E 15
 → B 38 - 40
 → A 2 - 7

B 34

A

B

C

D

E

F

G

H

I

K

L

M

N