


TEM Series (Multi-stage) Thermoelectric Module

Typical applications like: Photonic, medical and scientific instrument.

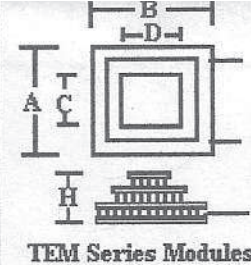

Part Number	Data obtained at hot plate temperature Th=27°C.				Dimension in mm		
	I _{max} (amps)	DT _{max} (° c)	V _{max} (volts)	Q _{max} (watts)	AxB	CxD	H
→ TES2-31-17-20	2.3	88	3.6	3.8	15x15	11.5x11.5	6.6
TES2-127-71-25S	3.2	88	14.6	21.4	29.7x29.7	22.6x22.6	5.8
TES2-127-127-30	3.6	88	14.6	15.3	30x30	30x30	6.5
TEC2-31-17-04	4.3	88	3.6	6.9	20x20	15x15	6.9
TEC2-71-31-04	4.6	88	8.2	13.6	30x30	20x20	6.9
TEC2-127-31-05	4.7	88	14.6	13.8	40x40	20x20	8.0
TEC2-127-63-04	4.2	88	14.6	26.0	40x40	40x40	8.1
TEC2-127-63-06	5.9	88	14.6	35.0	40x40	40x40	6.4
TEC2-127-70-09	8.9	88	14.6	59.1	62x62	62x62	8.9
TEC3-69-29-11-05	4.9	97	7.9	6.3	28.3x21.7	18.6x13	10.8
TEC3-71-31-17-03	3.5	97	8.2	7.0	30x30	15x15	10.4
TEC3-71-31-17-09S	8.5	97	8.2	16.8	44x44	22x22	12.95
TEC3-127-71-31-03	3.4	97	14.6	12.2	40x40	20x20	10.5
→ TEC3-127-71-31-06	5.0	97	14.6	18.1	40x40	20x20	9.1
TEC3-127-71-31-09S	8.2	97	14.6	29.3	62x62	31x31	13.2
TEC3-127-71-31L	8.2	97	14.6	29.3	62x62	31x31	13.2
TEC3-127-71-35-04S	3.2	97	14.6	13.1	40x40	30x30	10.6
TEC3-127-71-35-05S	4.0	97	14.6	16.1	40x40	30x30	9.9
TEC4-69-29-11-6-35	3.8	112	8.0	3.0	33x24	14.5x4.5	13.4
→ TEC4-97-49-17-7-05	4.4	112	11.2	4.0	35x35	10x10	10.7
TEC4-127-71-31-17-03	3.4	112	14.6	7.4	40x40	15x15	13.6
TEC4-127-71-31-17-03T	3.4	112	14.6	7.4	40x40	15x15	13.6
TEC4-127-71-	3.7	112	14.6	7.4	40x40	15x15	13.6