


First two digits is a spec. code      The rest is a lot #

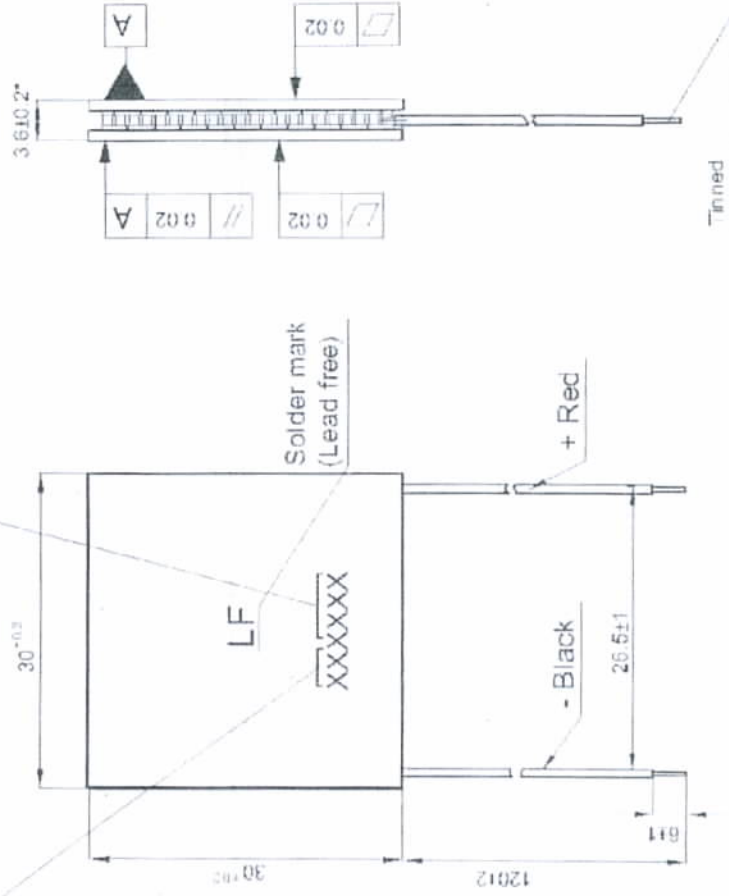

Technical Data	
V max	15.5 V
Q max	33 W
ΔT max	70°
I max	3.9 A
R	3.0 Ohm
Lead wires	20 AWG (0.5mm <sup>2</sup> ) PVC insulation (+90°C)
Sealing	No Sealing
Solder	Lead Free
Ceramics	Al <sub>2</sub> O <sub>3</sub> , white 96%
Maximum processing temperature	170°C
Tolerances for thermal and electrical parameters ±10%	
*Close height tolerance ±0.02 -upon request	

Thermoelectric module

Drawing No ND 051.00.00 C-31

-127-1.0-3.9 M