
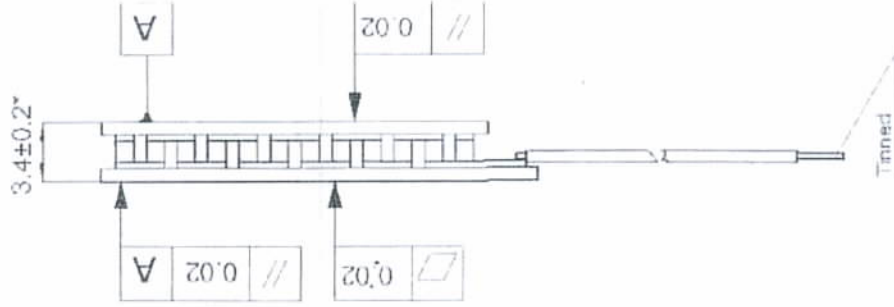


First two digits is a spec. code The rest is a lot #

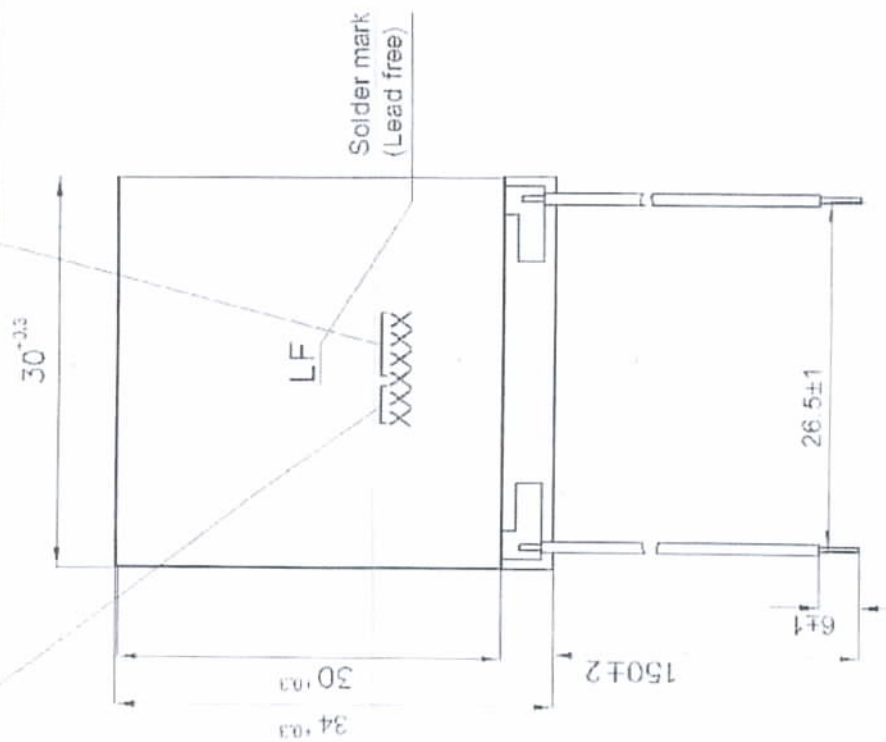

Technical Data	
V max	8.6 V
Q max	38 W
ΔT max	70°
I max	8.5 A
R	0.84 Ohm
Lead wires	20 AWG (0.5mm ²) PVC insulation (+90°C)
Sealing	No sealant
Solder	Lead Free
Ceramics	Al ₂ O ₃ , white 96%
Maximum processing temperature	170°C
Tolerances for thermal and electrical parameters ±10%	
*Close height tolerance ±0.02 -upon request	

Thermoelectric module

Drawing No ND 056.00.00 C-7

-71-1.4-8.5 M