


First two digits is a spec. code

The rest is a lot #

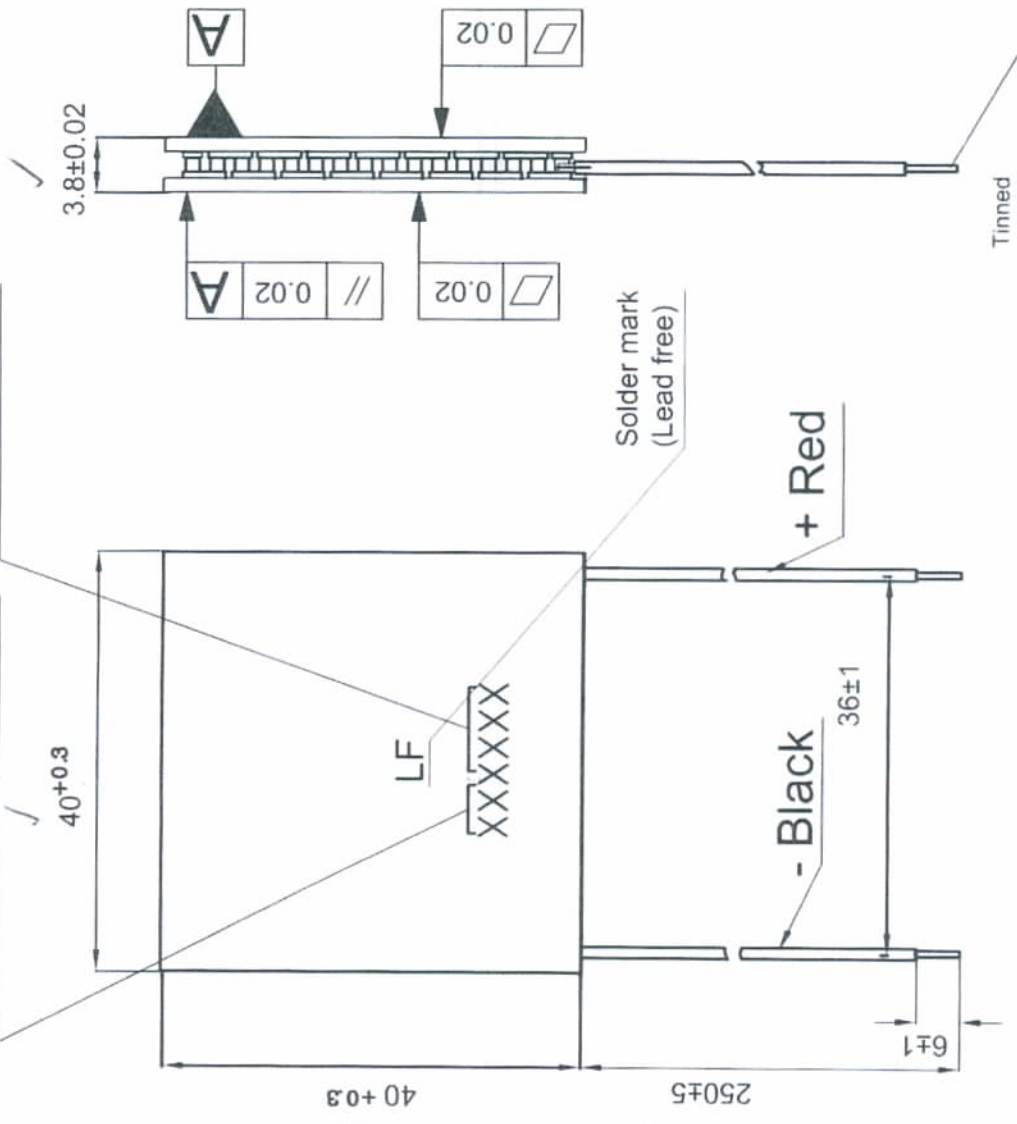

Technical Data	
V max	15.5 V ✓
Q max	70 W ✓
ΔT max	70° ✓
I max	8.5 A ✓
R	1.5 Ohm ✓
Lead wires	20 AWG (0.5mm ²) PVC insulation (+90°C)
Sealing	No sealing
Solder	Lead Free
Ceramics Al ₂ O ₃ , white 96%	
Maximum processing temperature +170°C	
Tolerances for thermal and electrical parameters ±10%	

Thermoelectric module

-127-1.4-8.5 MD

Drawing № ND 002.00.00 C-54