

Bus coupler - IBS IL 24 RB-T-PAC - 2861441

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



INTERBUS branch terminal, complete with accessories (connector plug and labeling field), with remote bus branch, 24 V DC

Product Features

- Diagnostic and status indicators



Key commercial data

| | |
|------------------|---------------|
| package_quantity | 1 |
| GTIN | 4017918894375 |

Technical data

Note:

| | |
|-------------------------|---|
| Utilization restriction | EMC: class A product, see manufacturer's declaration in the download area |
|-------------------------|---|

Dimensions

| | |
|--------|---------|
| Width | 12.2 mm |
| Height | 135 mm |
| Depth | 71.5 mm |

Ambient conditions

| | |
|--|---|
| Ambient temperature (operation) | -25 °C ... 55 °C |
| Ambient temperature (storage/transport) | -25 °C ... 85 °C |
| Permissible humidity (operation) | 10 % ... 95 % (according to DIN EN 61131-2) |
| Permissible humidity (storage/transport) | 10 % ... 95 % (according to DIN EN 61131-2) |
| Air pressure (operation) | 70 kPa ... 106 kPa (up to 3000 m above sea level) |
| Air pressure (storage/transport) | 70 kPa ... 106 kPa (up to 3000 m above sea level) |
| Degree of protection | IP20 |

Interfaces

| | |
|--------------------|--------------------|
| Fieldbus system | INTERBUS |
| Name | INTERBUS |
| Connection method | Inline data jumper |
| Transmission speed | 500 kBit/s |

Bus coupler - IBS IL 24 RB-T-PAC - 2861441

Technical data

Interfaces

| | |
|-----------------------------|-------------------------|
| Fieldbus system | INTERBUS |
| Name | INTERBUS |
| Connection method | Inline shield connector |
| Transmission speed | 500 kBit/s |
| Transmission physics | RS-485 |
| Fieldbus system | Lokalbus |
| Name | Inline local bus |
| Connection method | Inline data jumper |
| Transmission speed | 500 kBit/s |
| Transmission physics | Copper |

Power supply for module electronics

| | |
|-----------------------------|--|
| Supply voltage | 24 V DC (via voltage jumper) |
| Supply voltage range | 19.2 V DC ... 30 V DC (including all tolerances, including ripple) |

Inline potentials

| | |
|--|--------------------------------|
| I/O supply voltage U_{ANA} | 24 V DC (nominal value) |
| Current consumption from U_{ANA} | typ. 29 mA |
| Power consumption | max. 0.696 W (from U_{ANA}) |

General

| | |
|--------------------------------------|--|
| Weight | 67 g |
| Note on weight specifications | With connector |
| Mounting type | DIN rail |
| Protection class | III, IEC 61140, EN 61140, VDE 0140-1 |
| Test section | 5 V supply, incoming remote bus, 5 V supply outgoing remote bus, 5 V supply logic 500 V AC 50 Hz 1 min |
| Test section | Remote bus branch 500 V AC 50 Hz 1 min |
| Test section | Functional earth ground 500 V AC 50 Hz 1 min |

classifications

eCl@ss

| | |
|-------------------|----------|
| eCl@ss 4.0 | 27250304 |
| eCl@ss 4.1 | 27250203 |
| eCl@ss 5.0 | 27250203 |
| eCl@ss 5.1 | 27242608 |
| eCl@ss 6.0 | 27242608 |
| eCl@ss 7.0 | 27242608 |
| eCl@ss 8.0 | 27242608 |

ETIM

| | |
|-----------------|----------|
| ETIM 2.0 | EC001434 |
| ETIM 3.0 | EC001604 |

Bus coupler - IBS IL 24 RB-T-PAC - 2861441

classifications

ETIM

| | |
|-----------------|----------|
| ETIM 4.0 | EC001604 |
| ETIM 5.0 | EC001604 |

 
 
UNSPSC

| | |
|----------------------|----------|
| UNSPSC 6.01 | 43172015 |
| UNSPSC 7.0901 | 43201404 |
| UNSPSC 11 | 43172015 |
| UNSPSC 12.01 | 43201404 |
| UNSPSC 13.2 | 43201404 |

approvals











UL Listed / cUL Listed / UL Listed / cUL Listed / cULus Listed / UL Recognized / cUL Recognized / GOST / LR / GL / BV / DNV / ABS / RINA / GL-SW / BSH / UL Recognized / cUL Recognized / GOST / LR / GL / BV / DNV / ABS / GL-SW / BSH / cULus Recognized / GL /

Approval details



Bus coupler - IBS IL 24 RB-T-PAC - 2861441

          approvals



Bus coupler - IBS IL 24 RB-T-PAC - 2861441

approvals

DNV

GL-SW

cULus Recognized  US

accessories

Plug

IB IL SCN-6 SHIELD - 2726353



Labeling panel

IB IL FIELD 2 - 2727501



Terminal marking

ESL 62X10 - 0809492




Bus coupler - IBS IL 24 RB-T-PAC - 2861441

accessories


Drawings

Connection diagram

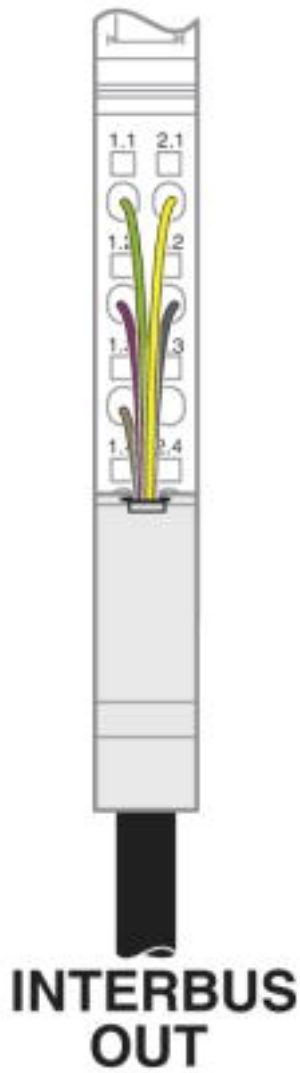

Bus coupler - IBS IL 24 RB-T-PAC - 2861441

Dimensioned drawing

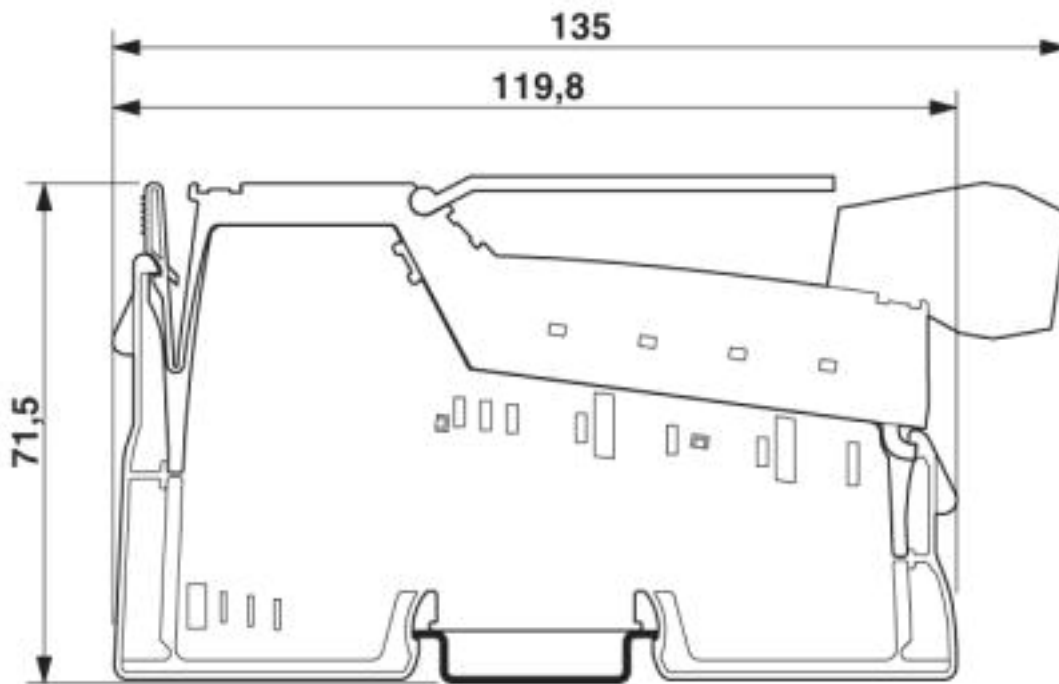

© Phoenix Contact 2013 - all rights reserved
<http://www.phoenixcontact.com>