

SAIL-M12GM12W-CD-1.5B

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com



The most reliable way of achieving connections between two I/O slaves or between the control and one I/O subscriber is by way of pre-assembled cables. The line of cables covers PROFIBUS, CANopen, DeviceNet™, EtherCAT and Ethernet.

General ordering data

Type	SAIL-M12GM12W-CD-1.5B
Order No.	1062190150
Version	Bus line, Connecting line, M12 / M12, No. of poles: 5, 1.5 m, pin, straight - socket, 90°, shielded: Yes, LED: No, Sheath material: PVC, Halogen: Yes
GTIN (EAN)	4032248811991
Qty.	1 pc(s).

SAIL-M12GM12W-CD-1.5B**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

Technische Daten**Dimensions and weights**

Net weight	125 g
------------	-------

Technical specifications for cable

No. of poles	5	Wire cross section	2 x 0.34 mm ² + 2 x 0.22 mm ²
shielded	Yes	Insulation	PVC
Colour coding	White, Blue, Red, Black	Sheath material	PVC
Sheathing colour	Black	Outer diameter	7.0 ± 0.3 mm
Cable length	1.5 m	Temperature range, moving, min.	-10 °C
Temperature range, moving, max.	80 °C	Temperature range, stationary, min.	-40 °C
Temperature range, stationary, max.	80 °C	Halogen	Yes
Suitable for cable carriers	No	Torsion resistance	0 °/m
Bending radius, min., stationary	5 x cable diameter	Bending radius, min., moving	10 x cable diameter
Acceleration	5 m/s ²	Speed	180 m/min
Resistant to welding beads	No		

General technical data

Version	pin, straight - socket, 90°	Contact tube diameter	M12 / M12
Housing main material	PUR	Threaded ring material	Brass, nickel-plated
Coding	A	Protection degree	IP 67
Contact surface	Gold-plated	LED	No
Rated voltage	125 V	Rated current	4 A
Insulation resistance	10 ⁸ Ω	Temperature range of housing	-25...+80 °C
Tightening torque	M12: 0.8 - 1.2 Nm	Plugging cycles	≥ 100
Pollution severity	3	jumpered	No

Classifications

ETIM 3.0	EC001855	eClass 5.1	27-06-91-90
eClass 6.2	27-06-03-07	eClass 7.1	27-06-03-07

Approvals

Approvals



ROHS


Conform

SAIL-M12GM12W-CD-1.5B

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com


Zeichnungen

Dimensioned drawing

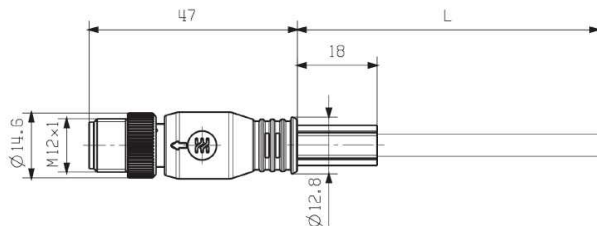

Male, straight


Pole scheme

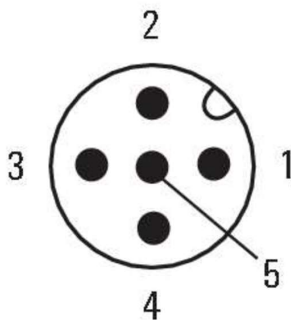

Pin


Wiring diagram

Dimensioned drawing

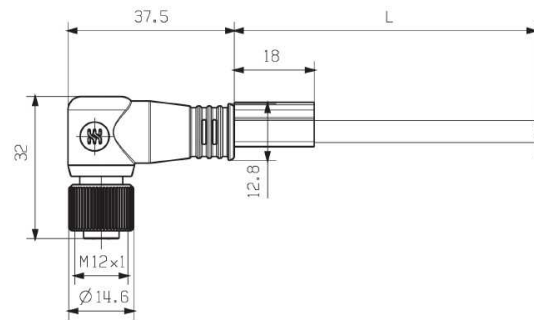

Socket angled

Pole scheme

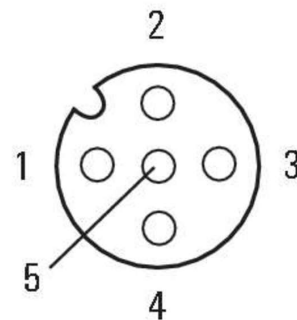

Socket

The ideal tool, the Screwty® with torque function



Light, securely screwed-in round plug-in connectors. Screwty set DM / VPE: 1 / Order No.: 1920000000 Adapters: M12, M12 F, M8, M8 F