

ACT20-FEED-IN-BASIC-S

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com



Power supply adapter modules for separate supply and distribution of the supply voltage: for the ACT20 series/ MICROSERIES signal converters.

The 22.5/6.1 mm wide power-feed modules are mounted directly adjacent to the analogue signal converters. Then the 24 VDC supply voltage is optionally bridged via the CH20M (ACT20-series) rail bus or simply bridged over using the pluggable ZQV 4N (MICROSERIES) cross-connectors.

The ACT20-Feed-In-PRO-S can also detect faults coming from any of the devices mounted on the CH20 bus mounting profile.

In the event of an error or fault, the integrated status relay sends a common alarm to the external controller. In addition, two power supply units (as primary and backup supply) can be connected to the ACT20 Feed-In PRO-S. Two feed-in modules mounted to the CH20 bus mounting profile guarantee a 100% redundant power supply. Three LEDs are used to show the status of the power supply and error messages.

The ACT20M-Feed-In PRO can also be used in Ex zone2 / Division2 applications.

General ordering data

Type	ACT20-FEED-IN-BASIC-S
Order No.	1282490000
GTIN (EAN)	4050118072730
Qty.	1 pc(s).

ACT20-FEED-IN-BASIC-S

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technische Daten

Dimensions and weights

Length	114.3 mm	Width	6.1 mm
Height	112.5 mm	Weight	70 g
Net weight	70 g		

Temperatures

Humidity	95 %, no condensation	Operating temperature	-20 °C...+60 °C
Ambient temperature	-20...+60 °C	Ambient temperature	-25 °C...+70 °C
Storage temperature	-20 °C...+85 °C		

Input

Input current	0.5...2.5 A DC	Input voltage, max.	26.4 V
Input voltage, min.	21.6 V		

output

Output current	Equivalent to input current	Output voltage, note	Corresponds to the input voltage
----------------	-----------------------------	----------------------	----------------------------------

General data

Ambient temperature	-25 °C...+70 °C	Degree of efficiency	100 %
Humidity	95 %, no condensation	Operating temperature	-20 °C...+60 °C
Standards	DIN EN 61010-1, DIN EN 60079	Weight	70 g

Rated data UL

UL certificate

Ratings IECEx/ATEX

Certificate No. (ATEX)	KEMA10ATEX0183X	Certificate No. (IECEx)	IECExKEM10.0090X
------------------------	-----------------	-------------------------	------------------

Classifications

eClass 6.2	27-21-01-07	eClass 7.1	27-21-01-07
------------	-------------	------------	-------------

Product information

Descriptive text accessories	DIN mounting rail, see Accessories
------------------------------	------------------------------------

Approvals

Approvals



ROHS	Conform
------	---------

ACT20-FEED-IN-BASIC-S

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

Technische Daten

Downloads

Package insert	instruction sheet.pdf
Declaration of Conformity	Declaration of Conformity.pdf

ACT20-FEED-IN-BASIC-S

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 16

D-32758 Detmold

 

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

Zeichnungen

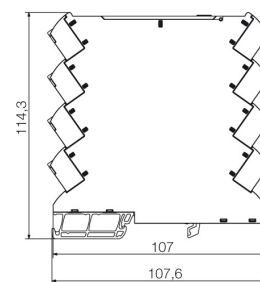

dimensions