

SAIL-7/8"BG-5-3.0U

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 16

 
D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com



Sensor/actuator cables are used for wiring sensors and actuators and for transmitting data or power in various applications. The moulded cable offers connected and tested connection of the plug-in connector to the cable ex-works. The cables may be exposed to a wide range of conditions, such as humidity, dust, heat, cold, shock or vibration.

The 7/8" cables tend to be used for power supply applications.

Is there something you have not managed to find or you feel needs explanation? Talk to us!

General ordering data

Type	SAIL-7/8"BG-5-3.0U
Order No.	1292190300
Version	Sensor/actuator line, 7/8", No. of poles: 5, 3 m, Female socket, straight, shielded: No, LED: No, Sheath material: PUR, Halogen: No
GTIN (EAN)	4050118088410
Qty.	1 pc(s).

SAIL-7/8"BG-5-3.0U

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technische Daten

Dimensions and weights

Net weight	220 g
------------	-------

Technical specifications for cable

No. of poles	5	Core cross-section	1.5 mm ²
shielded	No	Insulation	TPM
Colour coding	Brown, White, Blue, Black, green / yellow	Sheath material	PUR
Sheathing colour	Black	Outer diameter	8.7 mm
Cable length	3 m	Temperature range, moving, min.	-20 °C
Temperature range, moving, max.	80 °C	Temperature range, stationary, min.	-50 °C
Temperature range, stationary, max.	80 °C	Halogen	No
Suitable for cable carriers	No	Torsion resistance	0 °/m
Bending radius, min., moving	7.5 x cable diameter	Resistant to welding beads	No

General technical data

Version	Female socket, straight	Contact tube diameter	7/8"
Housing main material	PUR	Threaded ring material	Diecast zinc
Coding	none	Protection degree	IP 68, (when screwed in)
Contact surface	Au (Gold)	LED	No
Rated voltage	300 V	Rated current	9 A
Insulation resistance	10 ⁸ Ω	Temperature range of housing	-25...+85 °C
Plugging cycles	≥ 100	Pollution severity	3
jumpered	No		

Classifications

eClass 6.2	27-26-07-02	eClass 7.1	27-44-01-02
------------	-------------	------------	-------------

Approvals


ROHS	Conform
------	---------

SAIL-7/8"BG-5-3.0U


Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Zeichnungen

Dimensioned drawing

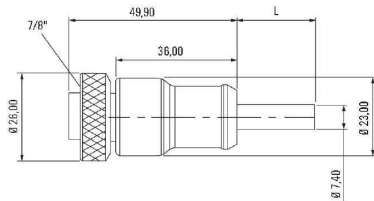

Pole scheme

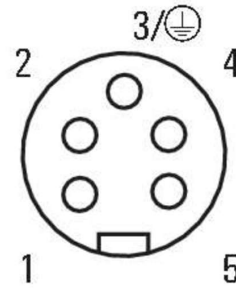

Circuit diagram

The ideal tool, the Screwty[®] with torque function



Light, securely screwed-in round plug-in connectors. Screwty set DM / VPE: 1 / Order No.: 1920000000 Adapters: M12, M12 F, M8, M8 F