

**SAI Passive
SAI-8-MHD 5P M12 OL****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com



Cable gland: M25 for cables with an outer insulation diameter from 13 mm to 18 mm. The SAI distributor with M25 cable gland is suitable among others for the following cable types:

- 21 x 0.50 mm
- 18 x 0.75 mm bis 21 x 0.75 mm
- 14 x 100 mm bis 20 x 100 mm
- 8 x 1.50 mm bis 16 x 1.50 mm

General ordering data

Type	SAI-8-MHD 5P M12 OL
Order No.	1740193000
Version	SAI Passive, Sensor-actuator passive distributor, Hood version with M25 outlet
GTIN (EAN)	4032248298938
Qty.	1 pc(s).

SAI Passive SAI-8-MHD 5P M12 OL

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Technische Daten

Dimensions and weights

Net weight	565 g
------------	-------

General data

Number of contact sockets	8	No. of poles	5
Cable gland	M 25	Distributor outlet	Hood version with M25 outlet
Insulation resistance	10 ⁹ Ω	Max. current-carrying capacity per slot	4 A
Housing main material	Pocan (base module), Zinc diecast (hood)	Contact material	CuZn
Contact surface	Gold-plated	Conductor O.D.	-

Classifications

ETIM 3.0	EC000830	eClass 6.2	27-06-91-90
eClass 7.1	27-06-91-90		

Approvals


Approvals	
ROHS	Conform

SAI Passive SAI-8-MHD 5P M12 OL

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Zeichnungen

Dimensioned drawing

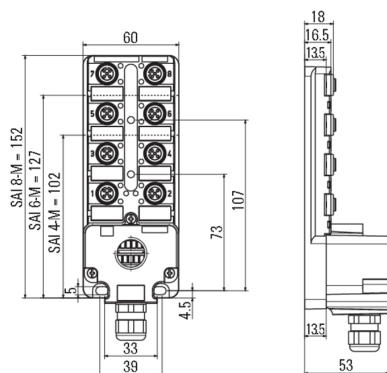

Circuit diagram

