

Device markers
THM MT30X 26/10 WS/M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16


D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

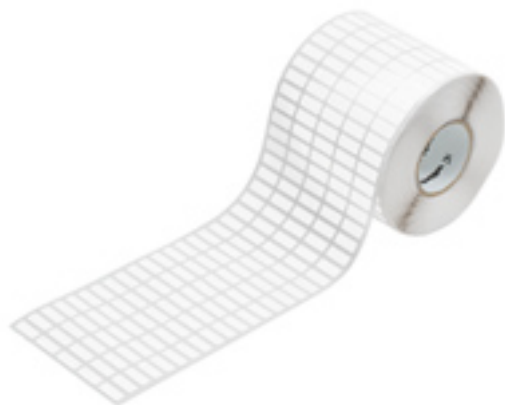

The ThermoMark labels offer brilliant printing quality thanks to the thermal transfer technology. Different materials and the user-friendly printing system under Windows optimise every marking effort.

- High-quality polyester labels in various colours or inexpensive paper labels are available
- Labels are automatically positioned in the printer for perfectly centred prints on each label.

General ordering data

Type	THM MT30X 26/10 WS/M
Order No.	1751761044
Version	Device markers, Label, 26 x 10 mm, Polyester, Colour: White
GTIN (EAN)	4032248001422
Qty.	1 pc(s).

Device markers THM MT30X 26/10 WS/M

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Technische Daten

Dimensions and weights

Length	26 mm	Width	10 mm
Net weight	529.8 g		

General data

Adhesive	Acrylate adhesive	Colour	White
Material	Polyester	Material colour according to resistance code	9
Number per roll	10,000	Number per sheet	10,000
Operating temperature range, max.	150 °C	Operating temperature range, min.	-29 °C
Printing method	Thermotransfer	UL 94 flammability rating	HB
UL 969 flammability rating	Yes		

Classifications

ETIM 3.0	EC001288	UNSPSC	30-21-18-01
eClass 5.1	27-14-91-29	eClass 6.2	27-14-91-29
eClass 7.1	27-14-91-29		

Approvals

Approvals	
ROHS	Conform

Downloads

M-Print® PRO configuration file	lab_thm_mt_30_26_10_mcf.zip
---------------------------------	---