

## SAI Passive SAI-8-F 3P M8 L 5M

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com



The new slim M8 line from Weidmüller. This range of products is characterised by the marking options at all connection positions. Even the 4-way distributor with 8-pole M12 has adequately large markers at all M8 connection positions. Furthermore, this distributor is shorter than many conventional M8 designs.

- Very narrow, short and flat M8 distributor.
- The range is supplied with 4 to 12 M8 connection positions, 3 or 4 poles.
- Hybrid variants of the M8 are also possible on request.
- The M8 line is equipped with transverse holes.

### General ordering data

Type	SAI-8-F 3P M8 L 5M
Order No.	<a href="#">1828680000</a>
Version	SAI Passive, Sensor-actuator passive distributor, M8, Fixed cable version, 5 m, Yes
GTIN (EAN)	4032248335329
Qty.	1 pc(s).

**Datenblatt**

**SAI Passive  
SAI-8-F 3P M8 L 5M**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

**Technische Daten**

**Dimensions and weights**

Height	18.2 mm	Net weight	487 g
--------	---------	------------	-------

**General data**

Number of contact sockets	8	Fire behaviour	V-0
Contact tube diameter	M8	No. of poles	3
Pollution severity	3	Distributor outlet	Fixed cable version
Insulation resistance	10 <sup>9</sup> Ω	Rated voltage , max.	30 V
Rated voltage , min.	10 V	Test voltage	1 kV
Current per signal	1 A	Total current	6 A
Max. current-carrying capacity per slot	2 A	Housing main material	Pocan
Housing colour	grey, RAL 7032	Screw socket	CuZn, nickel-plated
Contact material	CuZn	Contact surface	Gold-plated
Contact carrier material	PBT (UL 94 V0)	Sheathing stripping length	100 mm
Cable length	5 m	Conductor O.D.	-
Suitable for cable carriers	Yes	LED initiator	Yes
LED	Yes	LED colour for indicating operation	green
LED colour for I/O function	yellow		

**Classifications**

ETIM 3.0	EC001856	UNSPSC	30-21-18-01
eClass 6.2	27-06-91-90	eClass 7.1	27-06-91-90

**Approvals**

Approvals




ROHS Conform

**SAI Passive**  
**SAI-8-F 3P M8 L 5M**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 14-0  
Fax: +49 5231 14-292083  
www.weidmueller.com

**Zeichnungen**

**Dimensioned drawing**

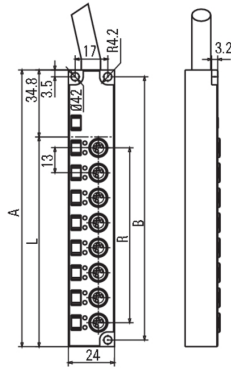

Steckplatze	A	B	L	R
4	82	85	57.2	38
6	118	111	83.2	65
8	144	137	109.2	91
10	170	163	135.2	117
12	196	189	161.2	143

**Circuit diagram**

