
 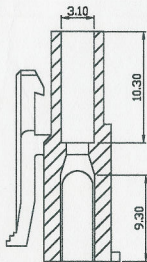



1300H-02 (ML)

Specifications:




- Poles: 2 Poles
- Material: Nylon UL94V-0




A-A

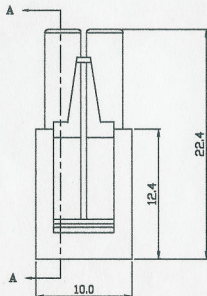

PRODUCT NO.	REVISION	DATE	DESCRIPTION	UNIT: mm	DRAWING	CHECKED	APPROVAL
HOUSING	A	8.20.1998	NEW DRAWING	TOLERANCE :			
PART NO			.000 :±0.08				
			.00 :±0.13				
				.0 :±0.25			

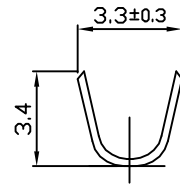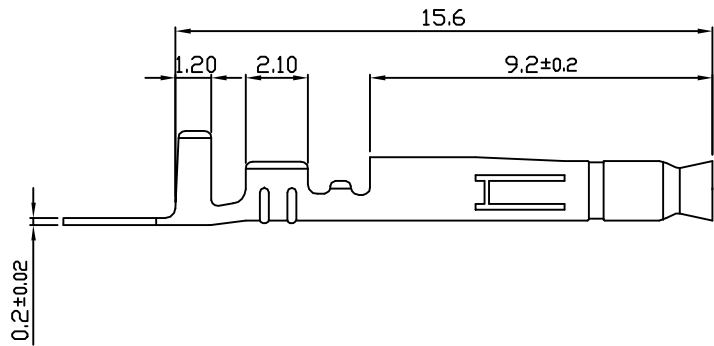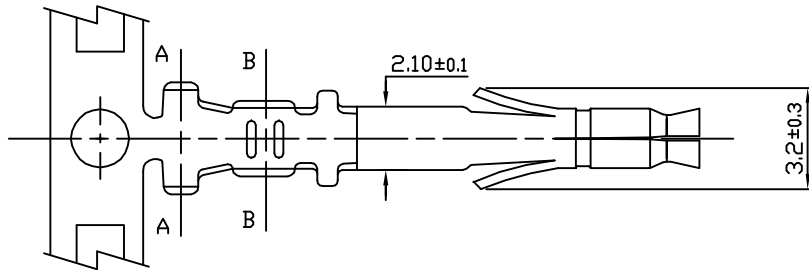

Section A-A

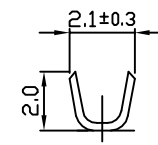

Section B-B

Specifications & Ordering Information:

Thickness	Material	Finish	Applicable Wire Range	Qty/reel	Suitable Housing
0.2	Brass	Tin-Plating	AWG: #20-#24	6,000 PCS	SM 1300H-02 ML

PRODUCT NO.	REVISION	DATE	DESCRIPTION	UNIT: mm	DRAWING	CHECKED	APPROVAL
TERMINAL	A	8.17.1999	NEW DRAWING	TOLERANCE :			
PART NO				.000 :±0.08			
1012T ML				.00 :±0.13			
				.0 :±0.25			