
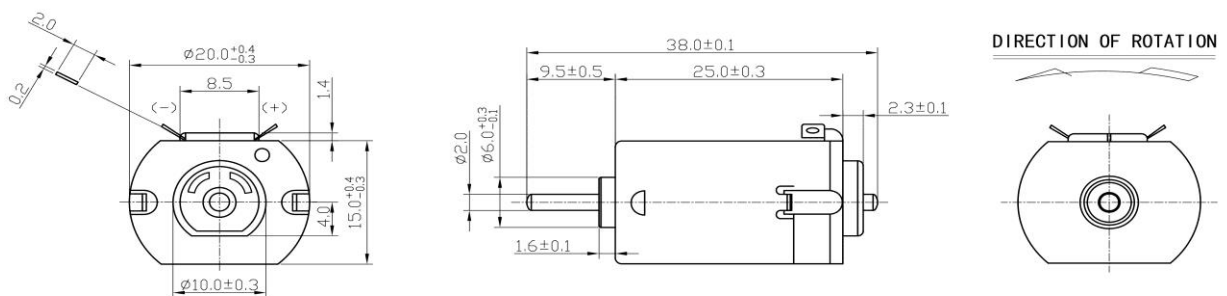


| MODEL | VOLTAGE | | NO LOAD | | AT MAXIMUM EFFICIENCY | | | | STARTING | | max. OUTPUT POWER W | POLES | CAPACITOR | BRUSHES |
|-------------------|-----------------|---------|---------|---------|-----------------------|---------|--------|--------------|----------|--------|------------------------|-------|-----------|---------|
| | Operating Range | Nominal | Speed | Current | Speed | Current | Torque | Output Power | Current | Torque | | | | |
| | VDC | VDC | rpm | A | rpm | A | mNm | W | A | mNm | | | | |
| FK-130SH-14190-RU | 9,0-15,0 | 14,8 | 26.500 | 0,15 | 21.730 | 0,66 | 2,12 | 4,81 | 3,00 | 11,76 | 8,15 | 3 | none | carbon |

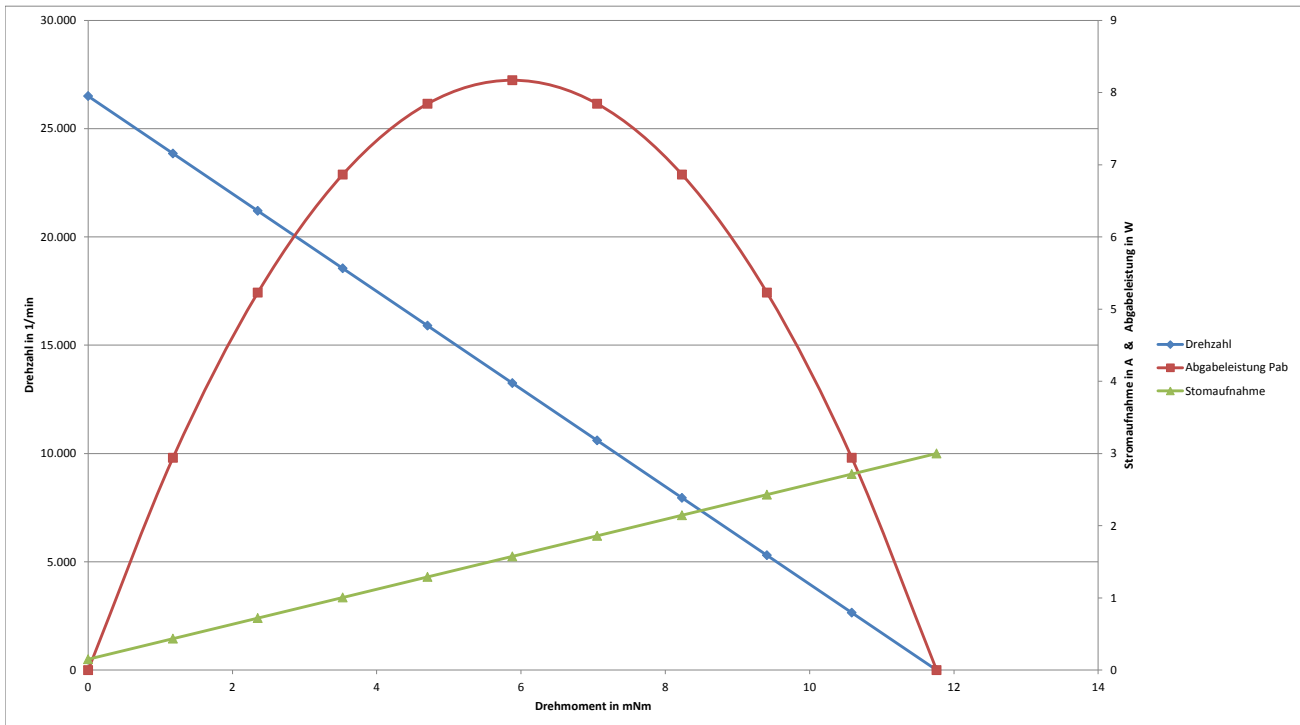

Irrtum und Druckfehler vorbehalten / Errors and Omissions excepted