
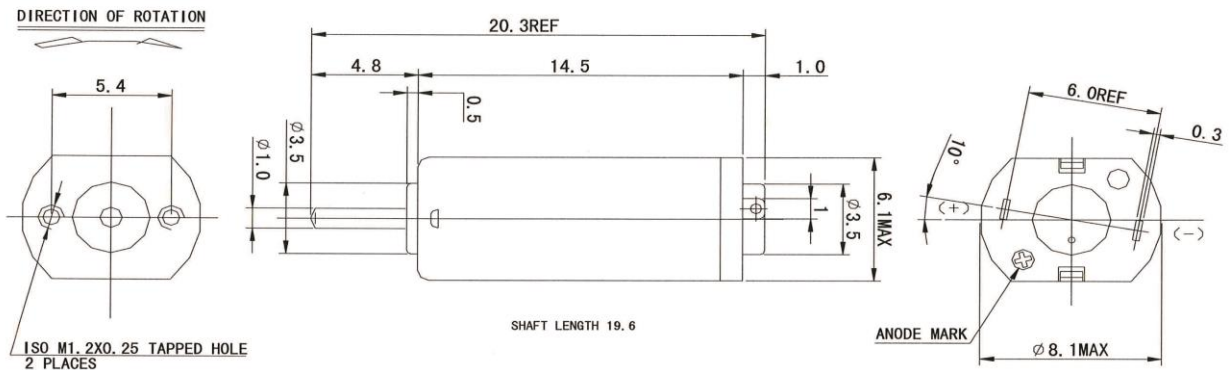


MODEL	VOLTAGE		NO LOAD		AT MAXIMUM EFFICIENCY				STARTING		max. OUTPUT POWER W	POLES	CAPACITOR	BRUSHES
	Operating Range	Nominal	Speed	Current	Speed	Current	Torque	Output Power	Current	Torque				
	VDC	VDC	rpm	A	rpm	A	mNm	W	A	mNm				
FF-K20WD-06205	1,5-3,0	3,0	11.608	0,02	8.350	0,05	0,09	0,08	0,13	0,31	0,10	3	none	metal

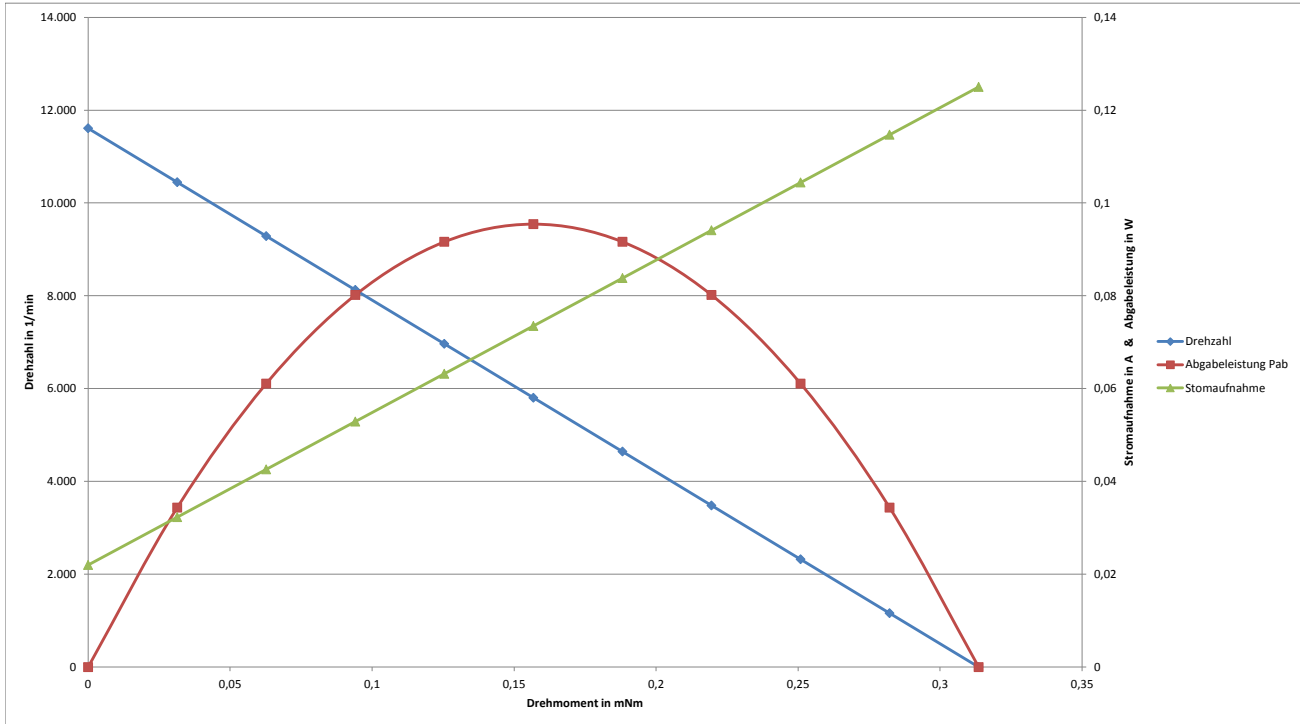

Irrtum und Druckfehler vorbehalten / Errors and Omissions excepted