




MODEL	VOLTAGE		NO LOAD		AT MAXIMUM EFFICIENCY				STARTING		max. OUTPUT POWER W	POLES	CAPACITOR	BRUSHES
	Operating Range	Nominal	Speed	Current	Speed	Current	Torque	Output Power	Current	Torque				
	VDC	VDC	rpm	A	rpm	A	mNm	W	A	mNm				
FF-N30VA-09210	1,5-3,6	2,5	5.029	0,02	3.901	0,07	0,26	0,11	0,23	1,18	0,16	3	none	carbon

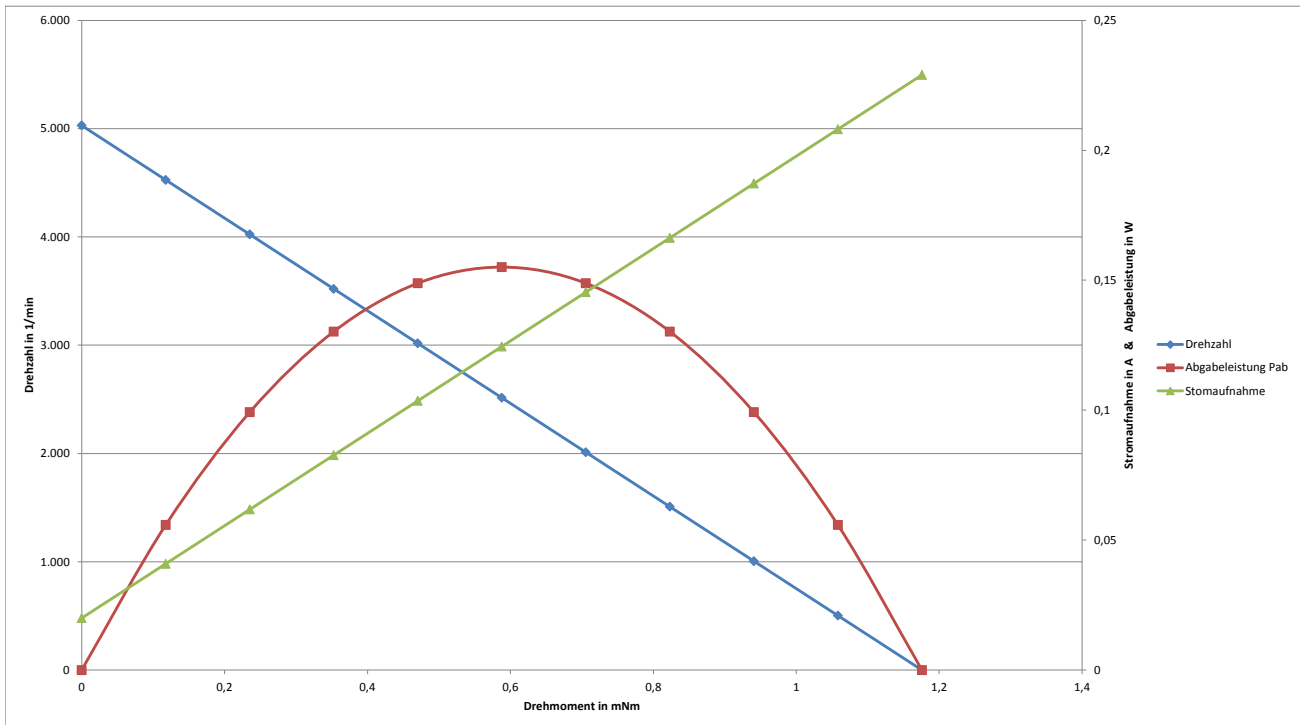

### DIRECTION OF ROTATION

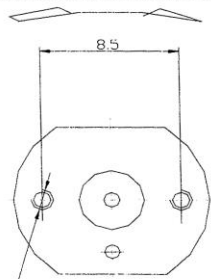

ISO M1, 4X0,3 TAPPED HOLE  
2 PLACES  
Usable machine screw length 1.2 max.  
form motor mounting surface.

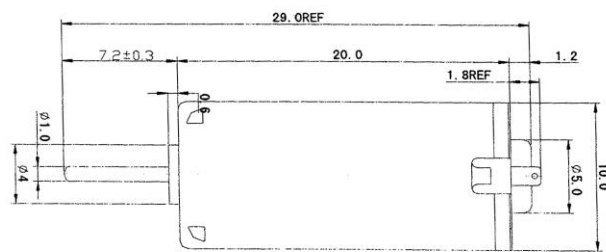

SHAFT LENGTH 27.5

