
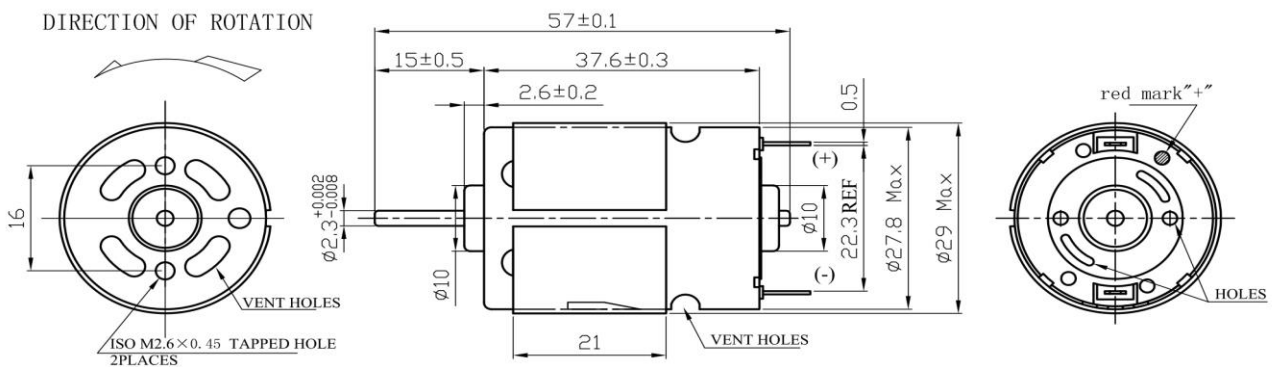


MODEL	VOLTAGE		NO LOAD		AT MAXIMUM EFFICIENCY				STARTING		max. OUTPUT POWER W	POLES	CAPACITOR	BRUSHES
	Operating Range	Nominal	Speed	Current	Speed	Current	Torque	Output Power	Current	Torque				
	VDC	VDC	rpm	A	rpm	A	mNm	W	A	mNm				
SR380SHP-4539P-57C	4,5-9,6	7,2	15.964	0,71	13.287	3,51	12,95	16,09	17,40	77,21	28,83	3	2x47nF	carbon

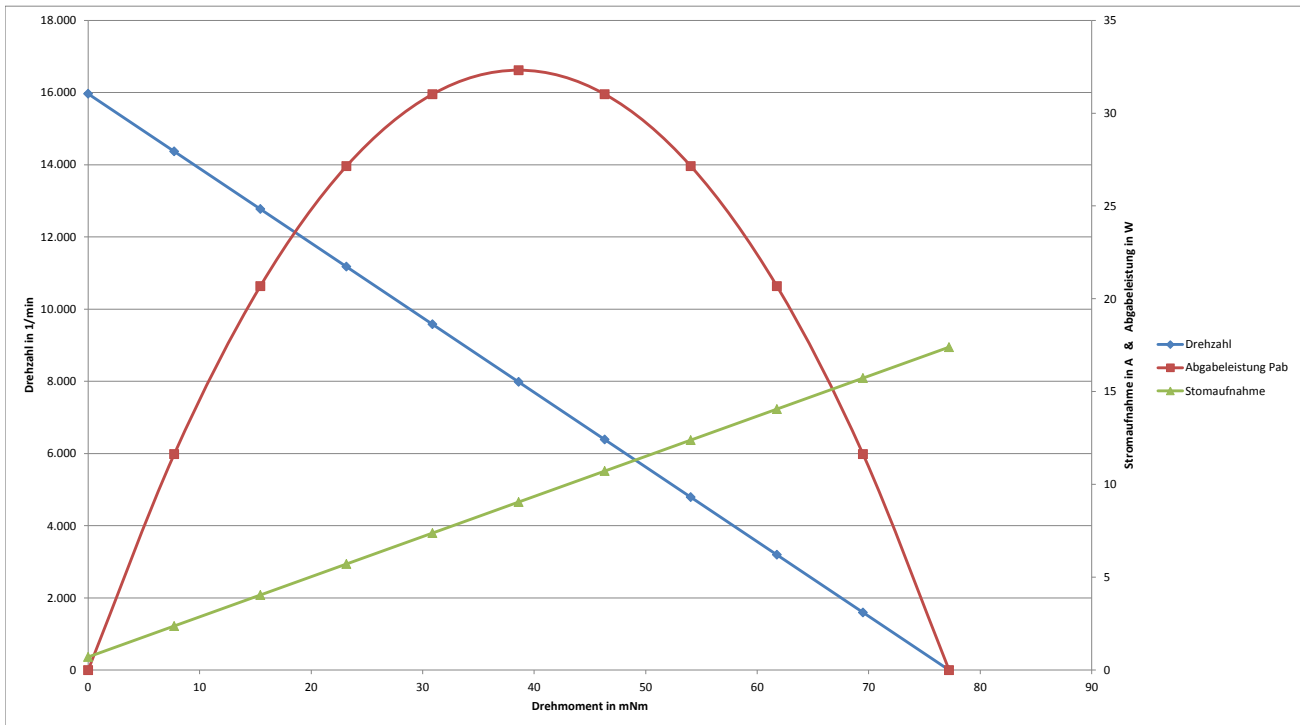

Irrtum und Druckfehler vorbehalten / Errors and Omissions excepted