


MODEL	VOLTAGE		NO LOAD		AT MAXIMUM EFFICIENCY				STARTING		max. OUTPUT POWER	POLES	CAPACITOR	BRUSHES	REDUCTION RATIO
	Operating Range	Nominal	Speed	Current	Speed	Current	Torque	Output Power	Current	Torque					
GM12F-N20VAVS-05440-298-4.4D-R	3,0-6,0	4,5	20	0,01	15	0,03	36,72	0,06	0,08	136,00	0,07	3	none	metal	298 : 1

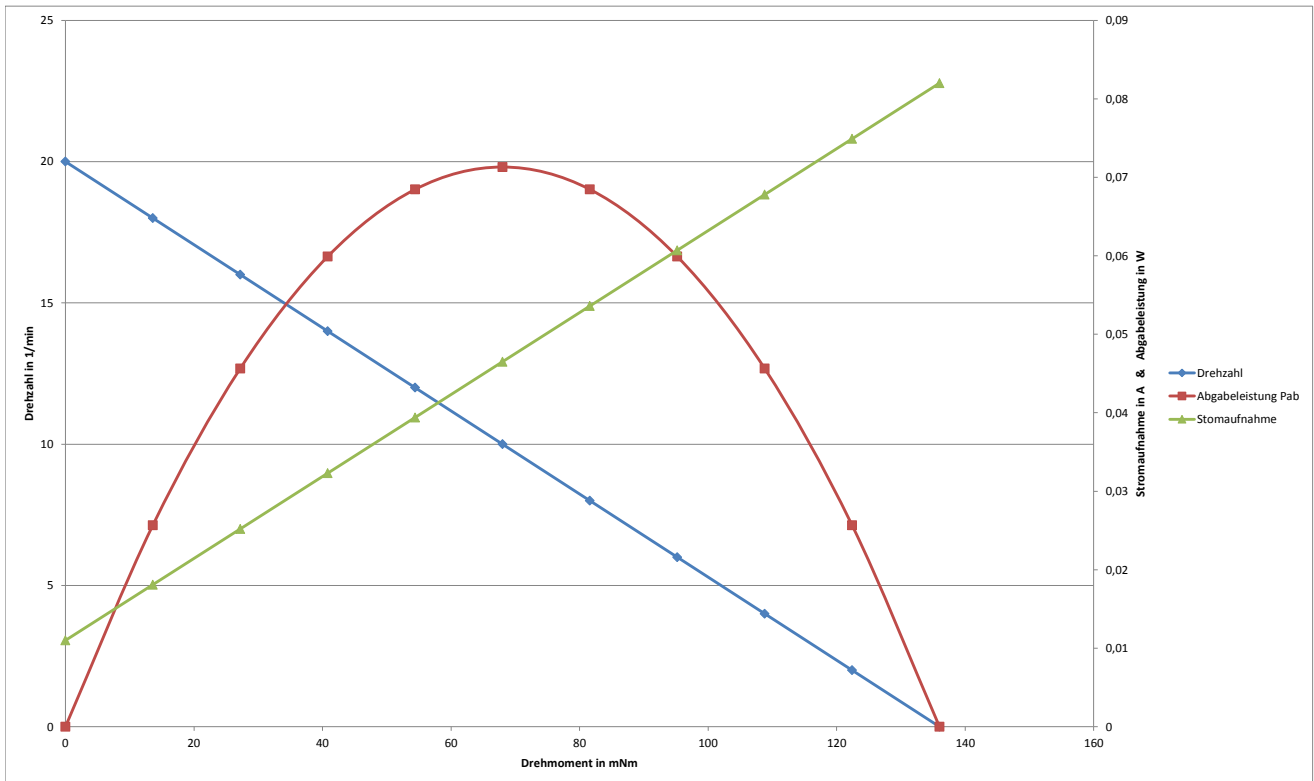

DIRECTION OF ROTATION

