
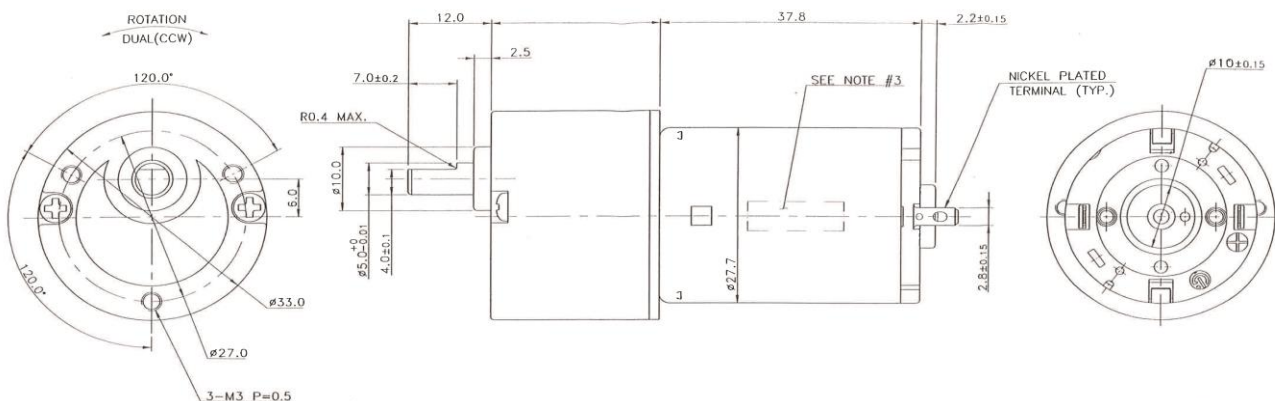


MODEL	VOLTAGE		NO LOAD		AT MAXIMUM EFFICIENCY				STARTING		max. OUTPUT POWER W	POLES	CAPACITOR	BRUSHES	REDUCTION RATIO
	Operating Range	Nominal	Speed	Current	Speed	Current	Torque	Output Power	Current	Torque					
	VDC	VDC	rpm	A	rpm	A	mNm	W	A	mNm					
33GN2738-132-GV-50:1	6,0-15,0	12,0	112	0,08	90	0,35	250,00	2,50	1,44	1314,00	3,80	5	none	Carbon	50 : 1

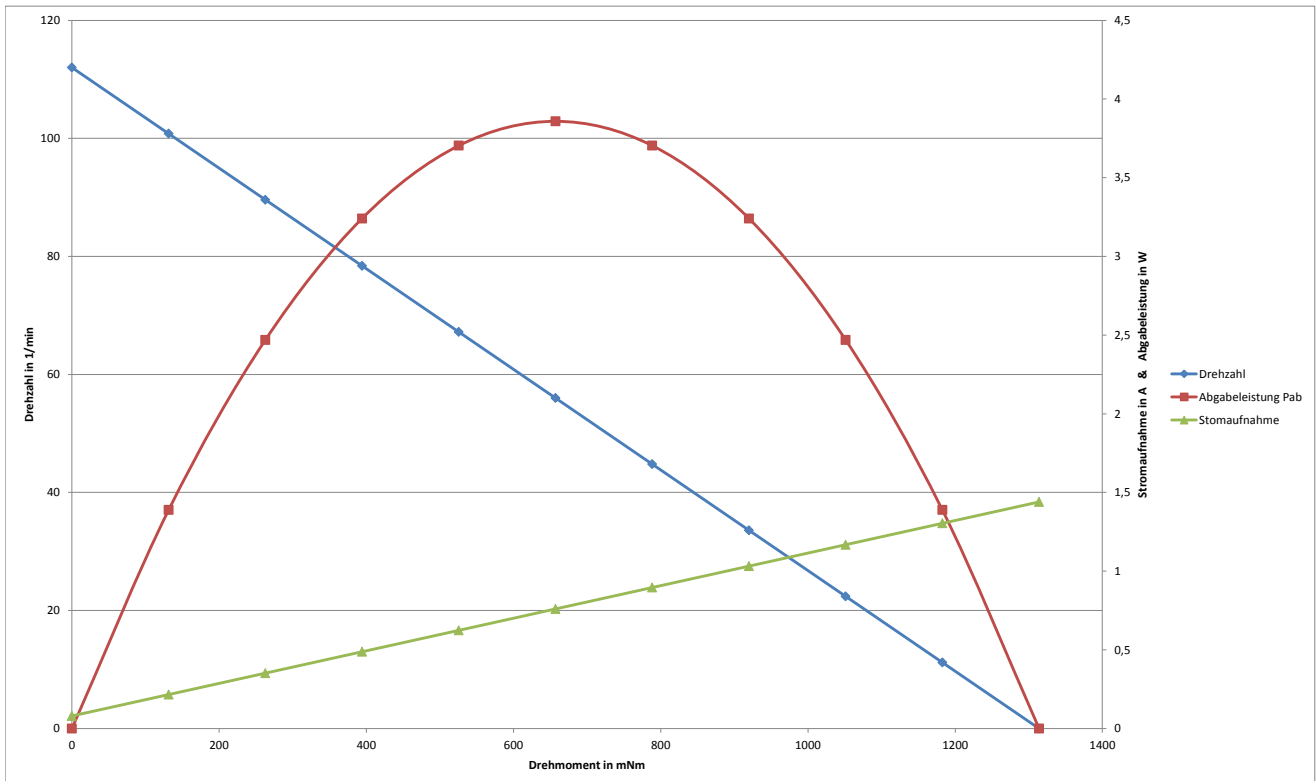

Irrtum und Druckfehler vorbehalten / Errors and Omissions excepted