
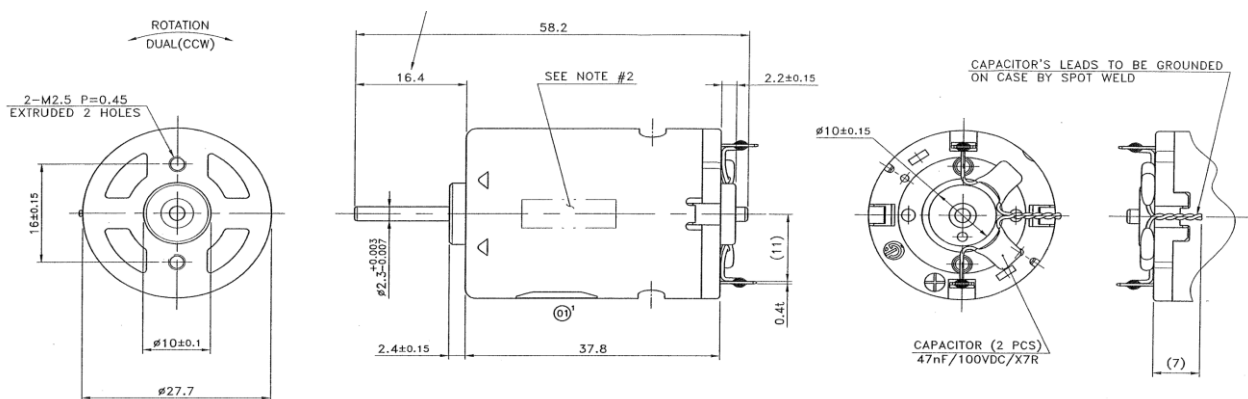


MODEL	VOLTAGE		NO LOAD		AT MAXIMUM EFFICIENCY			STARTING		max. OUTPUT POWER W	POLES	CAPACITOR	BRUSHES	
	Operating Range	Nominal	Speed	Current	Speed	Current	Torque	Output Power	Current					Torque
	VDC	VDC	rpm	A	rpm	A	mNm	W	A					mNm
2738-125-GC-5	6,0-24,0	12,0	5.800	0,08	4.750	0,40	5,00	2,50	1,59	27,26	4,30	5	2 x 47nF	carbon

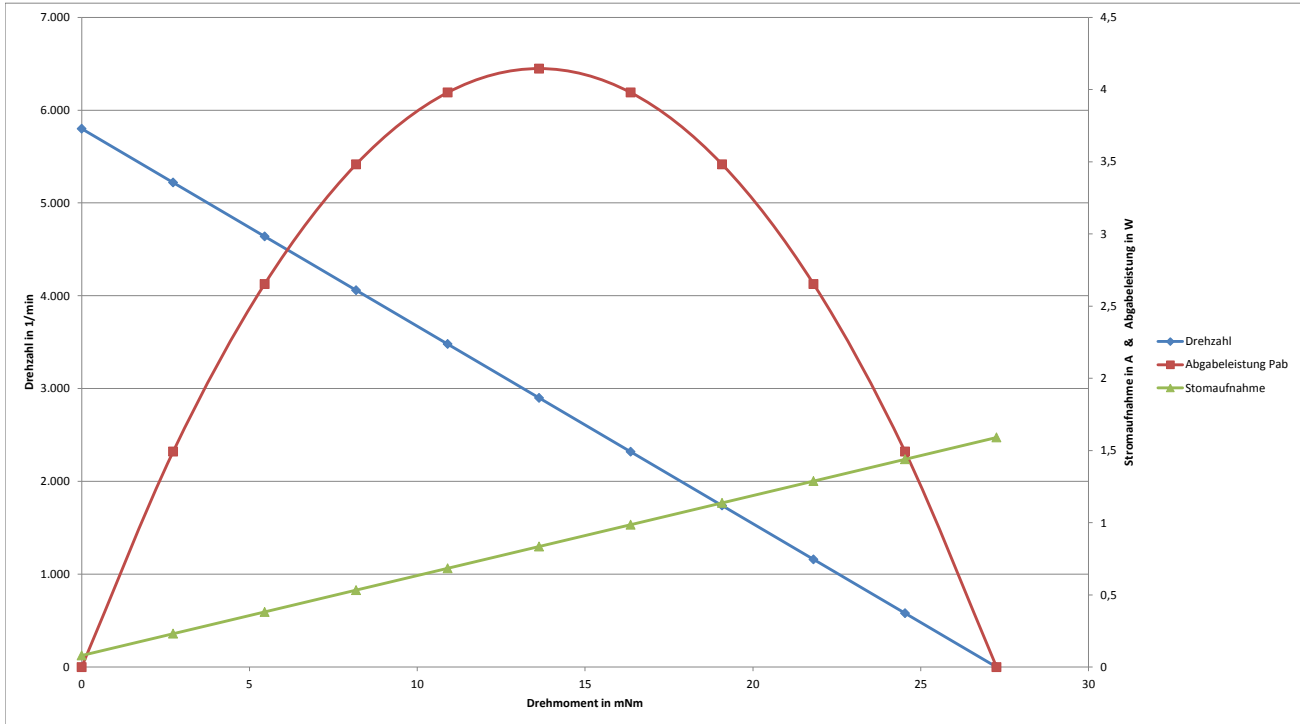

Irrtum und Druckfehler vorbehalten / Errors and Omissions excepted