
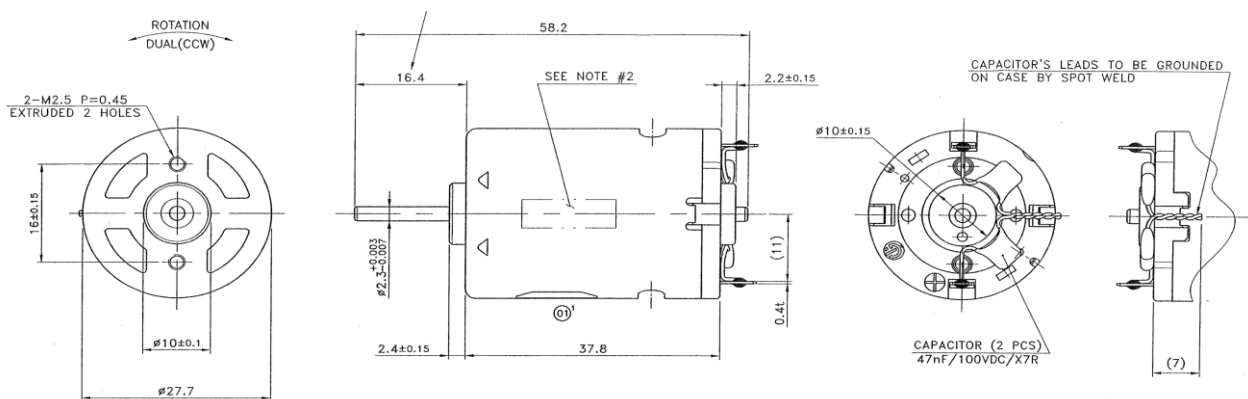


MODEL	VOLTAGE		NO LOAD		AT MAXIMUM EFFICIENCY			STARTING		max. OUTPUT POWER W	POLES	CAPACITOR	BRUSHES	
	Operating Range	Nominal	Speed	Current	Speed	Current	Torque	Output Power	Current					Torque
	VDC	VDC	rpm	A	rpm	A	mNm	W	A					mNm
2738-048-GC-3	3,0-9,0	6,0	14.800	0,50	12.300	3,20	10,00	12,50	8,60	55,00	3	2 x 47nF	carbon	

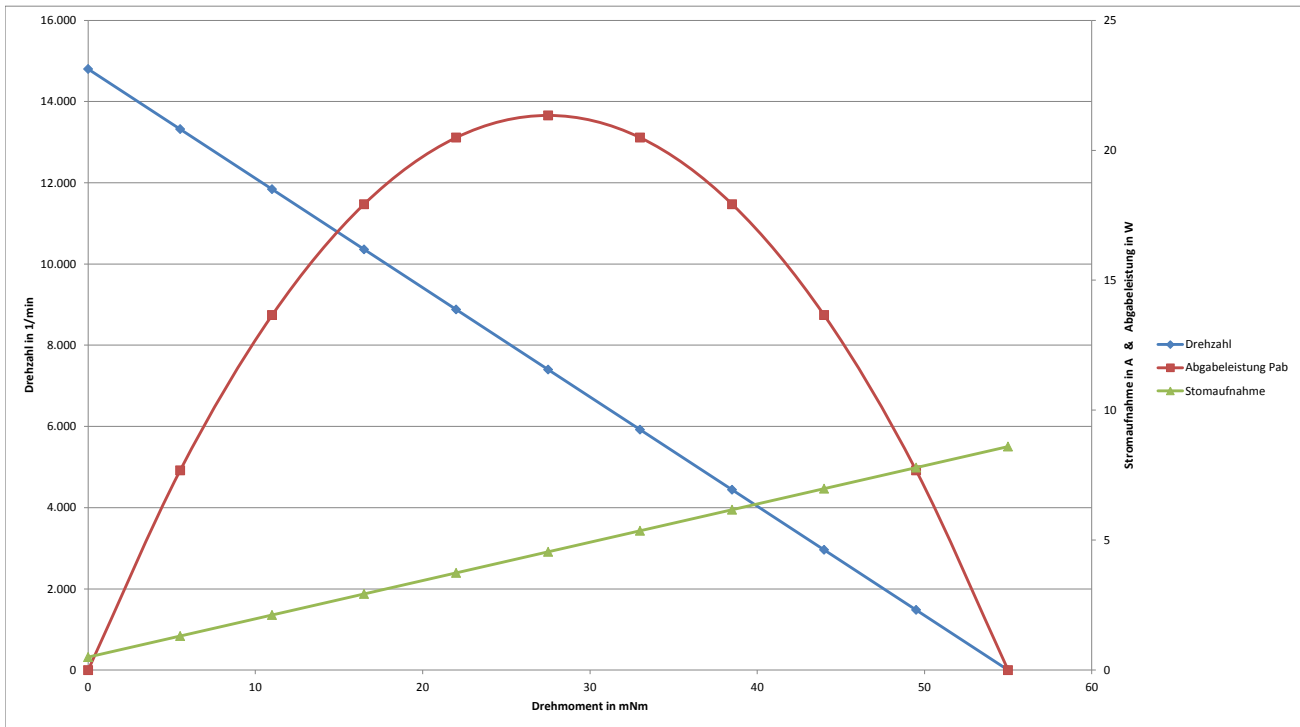

Irrtum und Druckfehler vorbehalten / Errors and Omissions excepted