


Cell Type KR-1800SCE


Specifications

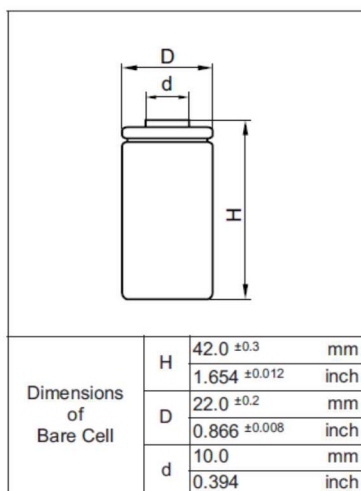


Nominal Capacity		1800mAh				
Nominal Voltage		1.2V				
Charging Current	Standard	180mA				
	Fast	2700mA				
Charging Time	Standard	14 to 16Hrs.				
	Fast	about 1Hr.				
Ambient Temperature	Charge	Standard	0°C to +45°C [+32°F to 113°F]			
		Fast	0°C to +45°C [+32°F to 113°F]			
	Discharge		-20°C to +60°C [-4°F to 140°F]			
	Storage		-30°C to +50°C [-22°F to 122°F]			
Internal Impedance (Av.) (at 50% discharge)		6.5mΩ (at 1000Hz)				
Weight		49g/1.73oz				
Dimensions(D)×(H) (with tube)		22.9	⁰ ₋₁	× 43.0	⁰ _{-1.2}	mm
		0.90	⁰ _{-0.04}	× 1.69	⁰ _{-0.05}	inch

Typical Characteristics


Charge

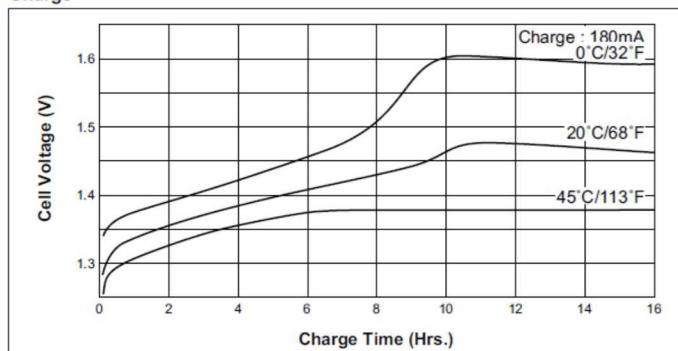


Discharge (at high rate)

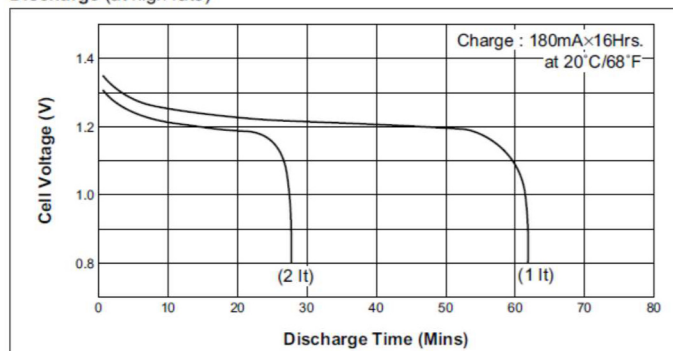


Charge

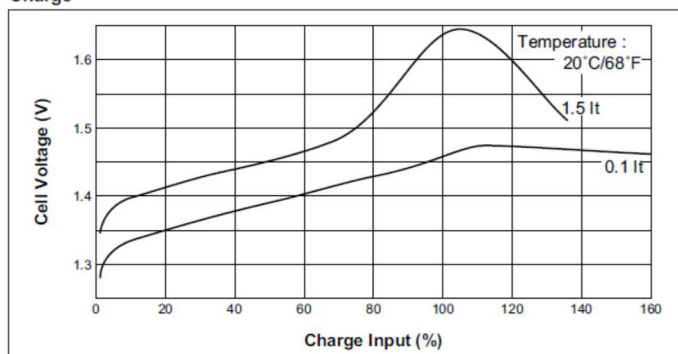

Discharge (at high rate)

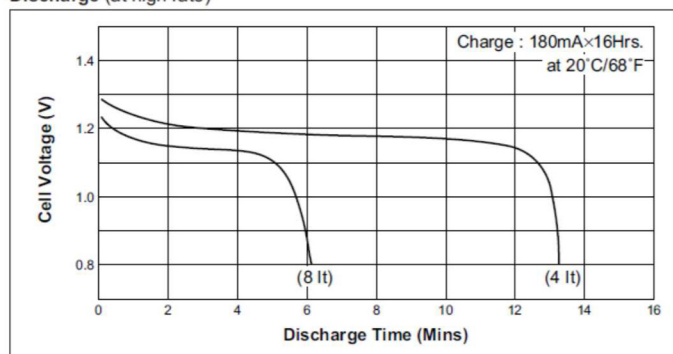

Discharge (at low rate)

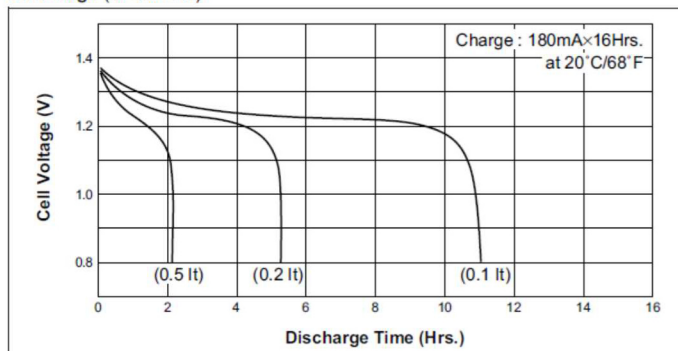

Temperature (Charge & Discharge)

