

H25,0/15**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16


D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

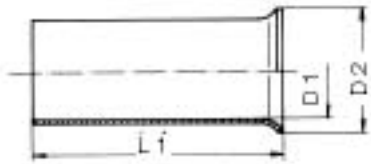

For conductors from 10.0 to 185.0 mm² (AWG 7 - 350 MCM)

tin-plated copper

dimensional tolerances to DIN 46228 part 1

- supplied loose in poly-bag

General ordering data

Type	H25,0/15
Order No.	0124400000
Version	Wire end ferrule, 25 mm ²
GTIN (EAN)	4008190071790
Qty.	250 pc(s).

H25,0/15

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technische Daten

Dimensions and weights

Length	15 mm	Net weight	0.62 g
--------	-------	------------	--------

Product data

Conductor cross-section	25 mm ²	Wire connection cross section AWG, max.	AWG 3
Contact surface diameter (D1)	7.3 mm	Collar diameter (D2)	9.5 mm

Classifications

ETIM 3.0	EC000005	UNSPSC	31-16-31-02
eClass 5.1	27-40-02-01	eClass 6.2	27-40-02-01
eClass 7.1	27-40-02-01		

Approvals

Approvals



ROHS Conform