


Accessories
STB 14/D6/4/M3 SAK10

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

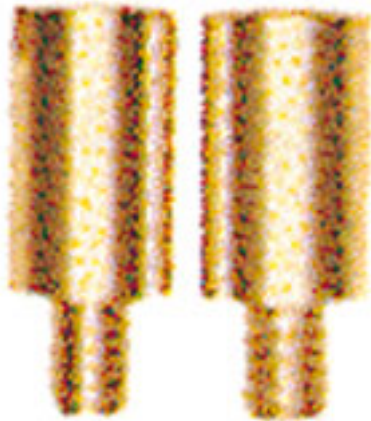

The SAKR disconnect terminals are available already fitted with sockets (see disconnect terminals). The sockets are equipped with a slit so that they can be actuated with a screwdriver. Weidmüller can supply special screwdrivers with a shoulder for this purpose.

General ordering data

Type	STB 14/D6/4/M3 SAK10
Order No.	0169900000
Version	Accessories, Socket
GTIN (EAN)	4008190076665
Qty.	50 pc(s).

Accessories

STB 14/D6/4/M3 SAK10

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
www.weidmueller.com

Technische Daten

Dimensions and weights

Height	19 mm	Net weight	1.8 g
Diameter	6 mm		

Temperatures

Operating temperature		Storage temperature	
Continuous operating temp., min.	-50 °C	Continuous operating temp., max.	100 °C

Additional technical data

Explosion-tested version	No	Installation advice	Direct mounting
Version	For the mounting rails		

Material data

Surface finish	galvanized	Material	Copper - zinc
Colour	Grey		

System specifications

Product family	Accessories
----------------	-------------

Classifications

ETIM 3.0	EC001134	UNSPSC	30-21-18-11
eClass 5.1	27-14-11-45	eClass 6.2	27-14-92-14
eClass 7.1	27-14-92-14		

Approvals

Approvals



ROHS Conform

Downloads

DXF	11455_STB_14-D6-4-M3_SAK10_DXF.dxf
STEP	0169900000_11455_STB_14-D6-4-M3_SAK10_STP.stp
3D Modell	