


H2,5/12

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

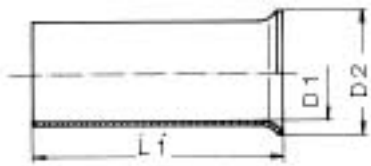

For conductors from 0.25 to 6,0 mm² (AWG 24 - 10)
tin-plated copper
dimensional tolerances to DIN 46228 part 1
• supplied loose in polybag

General ordering data

Type	H2,5/12
Order No.	0186100000
Version	Wire end ferrule, 2.5 mm ²
GTIN (EAN)	4008190172954
Qty.	1,000 pc(s).

H2,5/12

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technische Daten

Dimensions and weights

Length	12 mm	Net weight	0.113 g
--------	-------	------------	---------

Product data

Conductor cross-section	2.5 mm ²	Wire connection cross section AWG, max.	AWG 14
Contact surface diameter (D1)	2.2 mm	Collar diameter (D2)	3.4 mm

Classifications

ETIM 3.0	EC000005	UNSPSC	31-16-31-02
eClass 5.1	27-40-02-01	eClass 6.2	27-40-02-01
eClass 7.1	27-40-02-01		

Approvals

Approvals



ROHS Conform