


**SAK Series, Accessories**  
**QVS 3 SAKT1+2**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

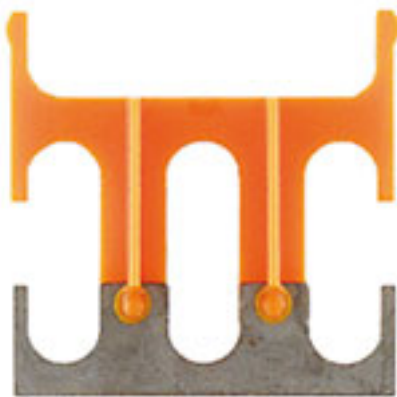

**QVS3 032930**

The versatile and extensive range of products - from 0.05 mm<sup>2</sup> to 300 mm<sup>2</sup> - means that you have diverse options for your applications at your disposal.  
 Hardened steel for mechanical strength and high-quality tinned copper for optimum conductivity. All materials comply with RoHS requirements and have been tested to current environment guidelines.

**General ordering data**

Type	QVS 3 SAKT1+2
Order No.	<a href="#">0329300000</a>
Version	SAK Series, Accessories, Cross-connector, Cross-connector, No. of poles: 3
GTIN (EAN)	4008190084714
Qty.	20 pc(s).

## SAK Series, Accessories QVS 3 SAKT1+2

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

## Technische Daten

### Dimensions and weights

Length	22 mm	Width	22 mm
Height	4.5 mm	Net weight	1.6 g

### Temperatures

Operating temperature		Storage temperature	
Continuous operating temp., min.	-50 °C	Continuous operating temp., max.	100 °C

### Additional technical data

Explosion-tested version	No	Installation advice	Direct mounting
Version	Cross-connector		

### Material data

Material	PA 66	Colour	Beige
UL 94 flammability rating	V-2		

### System specifications

Product family	SAK Series, Accessories
----------------	-------------------------

### Classifications

ETIM 3.0	EC000489	UNSPSC	30-21-18-01
eClass 5.1	27-14-11-40	eClass 6.2	27-14-11-40
eClass 7.1	27-14-11-40		

### Approvals

ROHS	Conform
------	---------