

H25,0/18**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16


D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

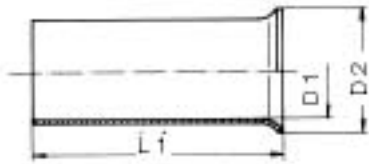

For conductors from 10.0 to 185.0 mm² (AWG 7 - 350 MCM)

tin-plated copper

dimensional tolerances to DIN 46228 part 1

- supplied loose in poly-bag

General ordering data

| | |
|------------|--------------------------------------|
| Type | H25,0/18 |
| Order No. | 0375300000 |
| Version | Wire end ferrule, 25 mm ² |
| GTIN (EAN) | 4008190145378 |
| Qty. | 100 pc(s). |

H25,0/18

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technische Daten

Dimensions and weights

| | | | |
|--------|-------|------------|--------|
| Length | 18 mm | Net weight | 0.76 g |
|--------|-------|------------|--------|

Product data

| | | | |
|-------------------------------|--------------------|---|--------|
| Conductor cross-section | 25 mm ² | Wire connection cross section AWG, max. | AWG 3 |
| Contact surface diameter (D1) | 7.3 mm | Collar diameter (D2) | 9.5 mm |

Classifications

| | | | |
|------------|-------------|------------|-------------|
| ETIM 3.0 | EC000005 | UNSPSC | 31-16-31-02 |
| eClass 5.1 | 27-40-02-01 | eClass 6.2 | 27-40-02-01 |
| eClass 7.1 | 27-40-02-01 | | |

Approvals

Approvals



ROHS Conform