

H10,0/18**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16


D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

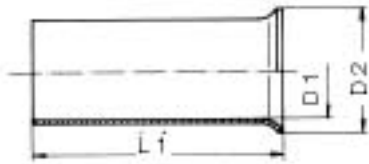

For conductors from 10.0 to 185.0 mm² (AWG 7 - 350 MCM)

tin-plated copper

dimensional tolerances to DIN 46228 part 1

- supplied loose in poly-bag

General ordering data

Type	H10,0/18
Order No.	0379300000
Version	Wire end ferrule, 10 mm ²
GTIN (EAN)	4008190156091
Qty.	500 pc(s).

Datenblatt

H10,0/18

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technische Daten

Dimensions and weights

Length	18 mm	Net weight	0.458 g
--------	-------	------------	---------

Product data

Conductor cross-section	10 mm ²	Wire connection cross section AWG, max.	AWG 7
Contact surface diameter (D1)	4.5 mm	Collar diameter (D2)	5.8 mm

Classifications

ETIM 3.0	EC000005	UNSPSC	31-16-31-02
eClass 5.1	27-40-02-01	eClass 6.2	27-40-02-01
eClass 7.1	27-40-02-01		

Approvals

Approvals



ROHS Conform