

**H1,0/12 GE****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16


D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

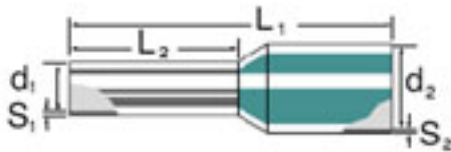

- supplied loose in polybag
- Weidmüller colour code
- DIN colour code

**General ordering data**

Type	H1,0/12 GE
Order No.	<a href="#">040970000</a>
Version	Wire end ferrule, 1 mm <sup>2</sup> , 6 mm, Colour code: Weidmüller, Yellow (RAL 1023)
GTIN (EAN)	4008190152222
Qty.	500 pc(s).

## H1,0/12 GE

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

## Technische Daten

### Dimensions and weights

Length	12 mm	Net weight	0.08 g
--------	-------	------------	--------

### Product data

Conductor cross-section	1 mm <sup>2</sup>	Wire connection cross section AWG, max.	AWG 17
Contact surface length (L2)	6 mm	Contact surface diameter (D1)	1.4 mm
Collar diameter (D2)	3 mm	Metal sleeve thickness (S1)	0.15 mm
Plastic collar thickness (S2)	0.25 mm		

### Classifications

ETIM 3.0	EC000005	UNSPSC	31-16-31-02
eClass 5.1	27-40-02-01	eClass 6.2	27-40-02-01
eClass 7.1	27-40-02-01		

### Approvals

Approvals



ROHS Conform