


SAK Series, Accessories
QB 4 WI RA8 IS

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

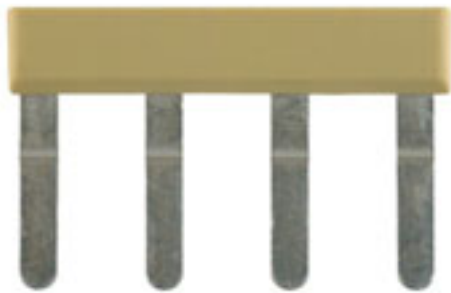

Cross-connection element, insulated
6.0, 6.5 mm and 8.0 mm pitches

General ordering data

Type	QB 4 WI RA8 IS
Order No.	0461300000
Version	SAK Series, Accessories, Cross-connector, for cross-connection link, No. of poles: 4
GTIN (EAN)	4008190025373
Qty.	50 pc(s).

SAK Series, Accessories
QB 4 WI RA8 IS

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technische Daten**Dimensions and weights**

Length	28 mm	Width	3 mm
Height	19 mm	Net weight	1.73 g

Temperatures

Operating temperature		Storage temperature	
Continuous operating temp., min.	-50 °C	Continuous operating temp., max.	100 °C

Additional technical data

Explosion-tested version	No	Installation advice	Direct mounting
Version	for cross-connection link		

Material data

Material	PA 66	Colour	Grey
UL 94 flammability rating	V-2		

System specifications

Product family	SAK Series, Accessories
----------------	-------------------------

Classifications

ETIM 3.0	EC000489	UNSPSC	30-21-18-01
eClass 5.1	27-14-11-40	eClass 6.2	27-14-11-40
eClass 7.1	27-14-11-40		

Product information

Descriptive text technical data	The mounting tolerances of the terminals must be taken into account. When used with a cross-connector, the rated cross-section should be reduced to the next smallest diameter.
---------------------------------	---

Approvals

Approvals



ROHS	Conform
------	---------

Downloads

STEP	0461300000_05503_QB_4_RA8_IS_STP.stp
------	--