

H6,0/20 SW**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16


D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

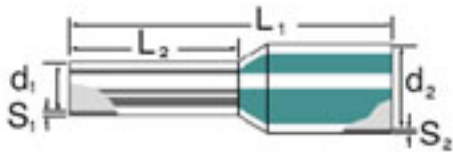

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Type	H6,0/20 SW
Order No.	053350000
Version	Wire end ferrule, 6 mm ² , 12 mm, Colour code: Weidmüller, Black (RAL 9011)
GTIN (EAN)	4008190183905
Qty.	100 pc(s).

H6,0/20 SW

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technische Daten

Dimensions and weights

Length	20 mm	Net weight	0.36 g
--------	-------	------------	--------

Product data

Conductor cross-section	6 mm ²	Wire connection cross section AWG, max.	AWG 10
Contact surface length (L2)	12 mm	Contact surface diameter (D1)	3.5 mm
Collar diameter (D2)	6.3 mm	Metal sleeve thickness (S1)	0.2 mm
Plastic collar thickness (S2)	0.3 mm		

Classifications

ETIM 3.0	EC000005	UNSPSC	31-16-31-02
eClass 5.1	27-40-02-01	eClass 6.2	27-40-02-01
eClass 7.1	27-40-02-01		

Approvals

Approvals



ROHS Conform