

H16,0/28 GN**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16


D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

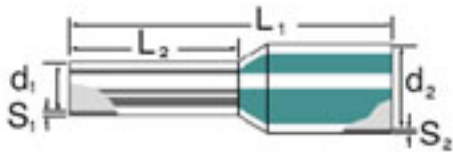

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Type	H16,0/28 GN
Order No.	0566000000
Version	Wire end ferrule, 16 mm ² , 18 mm, Colour code: Weidmüller, Green (RAL 6032)
GTIN (EAN)	4008190165406
Qty.	100 pc(s).

H16,0/28 GN

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technische Daten

Dimensions and weights

Length	28 mm	Net weight	0.85 g
--------	-------	------------	--------

Product data

Conductor cross-section	16 mm ²	Wire connection cross section AWG, max.	AWG 6
Contact surface length (L2)	18 mm	Contact surface diameter (D1)	5.8 mm
Collar diameter (D2)	8.8 mm	Metal sleeve thickness (S1)	0.2 mm
Plastic collar thickness (S2)	0.4 mm		

Classifications

ETIM 3.0	EC000005	UNSPSC	31-16-31-02
eClass 5.1	27-40-02-01	eClass 6.2	27-40-02-01
eClass 7.1	27-40-02-01		

Approvals

Approvals



ROHS Conform