


W-Series, Accessories
WBB ZA WDU1.5/BL 10/10

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

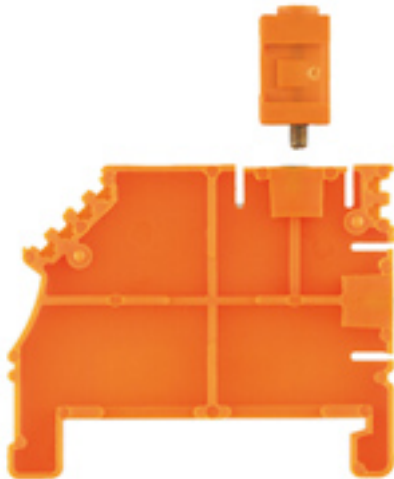

The versatile and extensive range of products - from 0.05 mm² to 300 mm² - means that you have diverse options for your applications at your disposal.
Hardened steel for mechanical strength and high-quality tinned copper for optimum conductivity. All materials comply with RoHS requirements and have been tested to current environment guidelines.

General ordering data

Type	WBB ZA WDU1.5/BL 10/10
Order No.	1068260000
Version	W-Series, Accessories, Fixing bracket, Blue, 5 mm
GTIN (EAN)	4008190015657
Qty.	10 pc(s).

W-Series, Accessories
WBB ZA WDU1.5/BL 10/10

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Technische Daten**Dimensions and weights**

Length	45.4 mm	Width	5 mm
Height	36.7 mm	Net weight	4.31 g

Temperatures

Operating temperature		Storage temperature	
Continuous operating temp., min.	-50 °C	Continuous operating temp., max.	100 °C

Additional technical data

Installation advice	Direct mounting	Version	End and intermediate plate
---------------------	-----------------	---------	----------------------------

Material data

Material	PA 66	Colour	Blue
UL 94 flammability rating	V-2		

System specifications

Product family	W-Series, Accessories
----------------	-----------------------

Classifications

ETIM 3.0	EC000886	UNSPSC	30-21-18-27
eClass 5.1	27-14-11-33	eClass 6.2	27-14-11-33
eClass 7.1	27-14-11-33		

Approvals

ROHS	Conform
------	---------