


## EMY-4530M (Artikel-Nr. 302007-07)

## EKULIT


### SPECIFICATIONS:

TYPE	UNIT	EMY-4030M
Sensitivity (0dB=1V/Pa. 1kHz)	dB	-65±4
Directivity		Omnidirectional
Impedance		Low impedance
Current consumption	mA	Max. 0.5
Standard operating voltage	V	1.5-10 (2.0)
Sensitivity reduction		within -3dB at 1.5V
S/N ratio	dB	more than 60
Current at 1kHz, 0dB=1V/μbar	mA	0.15
Operating Temperature	°C	-10~+45
Storage Temperature	°C	-20~+60


Dimensions :  
(Unit: mm)

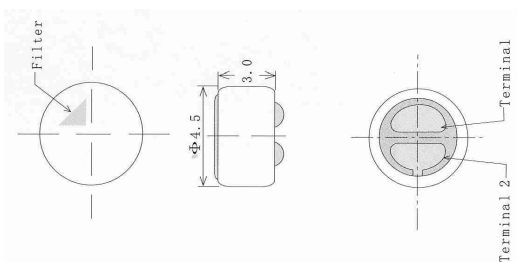

Typical Frequency response curve:

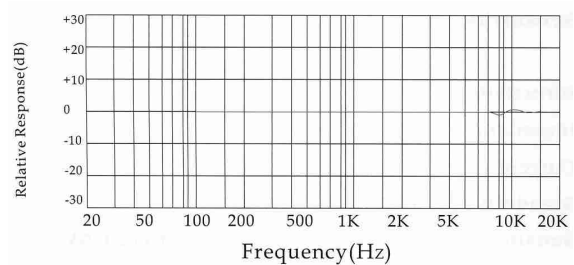

Schematic diagram :

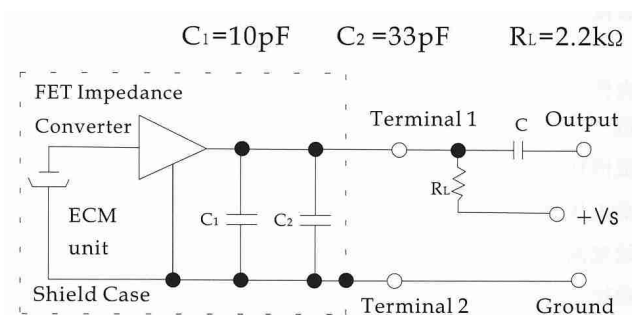

Picture :

