








# DMX CABLES

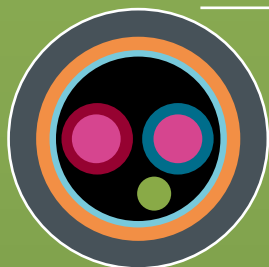

5.8 mm

-  Jacket
-  Shield, braided 16/4/0.1
-  AL/PT Foil, AL side towards conductors
-  Conductor Insulation
-  Conductor
-  Drain wire 7/0.2

## SPECIFICATIONS

Type:	Microphone Cable
Color:	black
Overall diameter:	5.8 mm +/- 0.2mm
Conductor area:	0,22 mm <sup>2</sup> / AWG 24
Conductor material:	copper wire screen
Composition of conductor:	28 x 0,10 mm
Screen material:	bare copper, OFC
Screen:	spiral wound
Conductor resistance:	80 Ohm / km
Capacity:	<90 pF/m
Overall jacket material:	PVC mat

Item No.	Description	Length
K3DMF0050	DMX Cable XLR male to XLR female	0.5 m
K3DMF0150	DMX Cable XLR male to XLR female	1.5 m
K3DMF0300	DMX Cable XLR male to XLR female	3.0 m
K3DMF0600	DMX Cable XLR male to XLR female	6.0 m
K3DMF1000	DMX Cable XLR male to XLR female	10.0 m
K3DMF1500	DMX Cable XLR male to XLR female	15.0 m
K3DMF2000	DMX Cable XLR male to XLR female	20.0 m
K3DMF3000	DMX Cable XLR male to XLR female	30.0 m

