



OMNITRONIC CSE Ceiling speaker

Ceiling-mount speaker white

- 1-way system
- 100 V transformer with 2 power taps
- 13.5 to 20 cm full-range speaker (5.25 to 8")
- For indoor PA systems

No. 80710240CSE-5
 No. 80710241CSE-6
 No. 80710242CSE-8

OMNITRONIC CSP-6 Ceiling speaker

Ceiling-mount speaker white

- 15 cm full-range speaker (6")
- 100 V transformer with 2 power taps


No. 80710250 CSP-6

OMNITRONIC CSC Ceiling speaker

Ceiling mount speaker with firedome white

- 1-way system
- Full range speaker
- Safety version with firedome

No. 80710260 CSC-4
 No. 80710280 CSC-6

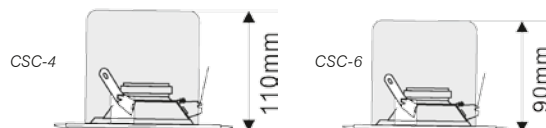

100V

Technical specifications:

Device:	CSE-5	CSE-6	CSE-8	CSP-6	CSC-4	CSC-6
Input voltage:	100 V	100 V	100 V	100 V	100 V	100 V
Components:	13.5 cm speaker (5.25")	16.5 cm speaker (6")	20 cm speaker (8")	15 cm speaker (6")	10 cm speaker (4")	15 cm speaker (6")
Rated power:	3 W, 6 W RMS	3 W, 6 W RMS	5 W, 10 W RMS	3 W, 6 W RMS	3 W, 6 W RMS	3 W, 6 W RMS
Sensitivity (1 W/1 m):	93 dB, ±3 dB	93 dB, ±3 dB	93 dB, ±3 dB	91 dB, ±3 dB	90 dB ±3 dB	92 dB, ±3 dB
Max. SPL (1 m):	97 dB	97 dB	99 dB	97 dB	94 dB	96 dB
Frequency range:	100 Hz - 20 kHz	100 Hz - 20 kHz	100 Hz - 20 kHz	100 Hz - 17 kHz	150 Hz - 15 kHz	100 Hz - 18 kHz
Dimensions (D x D):	175 x 55 mm	188 x 76 mm	230 x 90 mm	188 x 70 mm	180 x 110 mm	200 x 90 mm
Mounting cutout:	145 mm ø	170 mm ø	200 mm ø	164 mm ø	150 mm ø	185 mm ø
Weight:	500 g	750 g	1 kg	500 g	800 g	900 g



100V

OMNITRONIC CSS/CSQ Ceiling speaker

Ceiling mount speaker square

- 2-way system with 10-20 cm woofer (4-8") and 1.5 cm tweeter (0.5/1")
- 3 power taps
- For indoor PA systems
- Easy frontal mounting

No. 80710330 CSS-5
 No. 80710340 CSS-6
 No. 80710350 CSS-8

 No. 80710335 CSQ-4
 No. 80710345 CSQ-5
 No. 80710355 CSQ-6



Technical specifications:

Device:	CSS-5	CSS-6	CSS-8	CSQ-4	CSQ-5	CSQ-6
Input voltage:	100 V	100 V	100 V	100 V	100 V	100 V
Components:	13 cm woofer (5"), 1.5 cm tweeter (0.5")	16.5 cm woofer (6.5"), 1.5 cm tweeter (0.5")	20 cm woofer (8"), 2.5 cm tweeter (1")	10 cm woofer (4"), 1.5 cm tweeter (0.5")	13 cm woofer (5"), 1.5 cm tweeter (0.5")	15 cm woofer (6"), 1.5 cm tweeter (0.5")
Rated power:	1.25 W, 2.5 W, 5 W RMS	1.25 W, 2 W, 5 W RMS	2.5 W, 5 W, 10 W RMS	5 W, 10 W 20 W RMS	7.5 W, 15 W, 30 W RMS	10 W, 20 W, 40 W RMS
Sensitivity (1 W/1 m):	92 dB	92 dB	92 dB	89 dB, ±3 dB	89 dB, ±3 dB	87 dB, ±3 dB
Frequency range:	100 Hz - 15 kHz	100 Hz - 15 kHz	80 Hz - 15 kHz	90 Hz - 18 kHz	90 Hz - 18 kHz	50 Hz - 18 kHz
Dimensions (H x W x D):	280 x 190 x 60 mm	305 x 220 x 60 mm	373 x 273 x 60 mm	190 x 190 x 80 mm	220 x 220 x 90 mm	255 x 255 x 95 mm
Mounting cutout:	243 x 155 mm	270 x 185 mm	326 x 226 mm	155 x 155 mm	185 x 185 mm	220 x 220 mm
Weight:	1.2 kg	1.5 kg	2 kg	1.3 kg	1.7 kg	2.2 kg