



4/8 ohm IP44

OMNITRONIC NOR PA horn speaker

Horn speaker

- Humidity-proof
- 8 ohms speaker system
- Aluminum housing

No. 80710951 NOH-15R
 No. 80710953 NOH-40R
 No. 80710958 NOH-30R

Technical specifications

Device:	NOR-15R	NOR-40R	NOR-30R
Rated power:	15 W RMS	40 W RMS	30 W RMS
Impedance:	8 Ohm	8 Ohm	8 Ohm
SPL (1 W/ 1 m):	101 dB	106 dB	110 dB
Frequency range:	500 Hz - 5 kHz	300 Hz - 3 kHz	300 Hz - 8 kHz
Dimensions (D x L):	210 x 210 mm	400 x 345 mm	310 x 295 mm
Weight:	1 kg	2,5 kg	1 kg



4/8 ohm IP44

OMNITRONIC NOH PA horn speaker

Horn speaker

- Humidity-proof
- 8 ohm speaker system
- Aluminum housing

No. 80710954 NOH-25S
 No. 80710955 NOH-35S
 No. 80710956 NOH-40S

Technical specifications

Device:	NOH-25S	NOH-35S	NOH-40S
Rated power:	25 W RMS	35 W RMS	40 W RMS
Impedance:	8 Ohm	8 Ohm	8 Ohm
SPL (1 W/ 1 m):	100 dB	102 dB	105 dB
Frequency range:	400 Hz - 4 kHz	400 Hz - 5 kHz	340 Hz - 4 kHz
Dimensions (D x L):	200 x 155 x 205 mm	280 x 190 x 240 mm	345 x 287 x 260 mm
Weight:	1 kg	1 kg	2 kg


IP44 100V

No. 80710811 HS-35
 No. 80710821 HS-45

OMNITRONIC HS PA horn speaker

Horn speaker

- Weather-proof ABS plastic housing (IP 56)
- Swivable mounting bracket

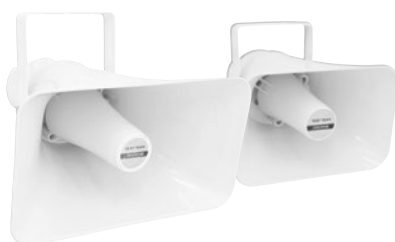

Technical specifications:

Device:	HS-35	HS-45
Input voltage:	100 V	100 V
Rated power:	7.5, 15 W RMS (white), COM (black)	15 W, 30 W RMS
Max. SPL:	105 dB (1 m)	108 dB
Frequency range:	400 Hz - 5 kHz	350 Hz - 8 kHz
Protection rating:	IP 56	IP 56
Dimensions (H x W x D):	232 x 228 x 281 mm	305 x 325 x 325 mm
Weight:	1.4 kg	2 kg