



IT-100TW

Order No.: 16.2570

PRODUCTINFOS

The music horns from MONACOR are the state-of-the-art solution in order to use the full range of a horn speaker with a clearly extended frequency range.

The 2-way technology with a dynamic cone bass-midrange speaker and a horn tweeter allows for an increase in the sound quality and permits to radiate the keynotes of voices and instruments which cannot be achieved by conventional horn speakers. The music horns are a perfect solution whenever an optimum voice volume and/or a more complete music transmission is required.

Weatherproof horn speaker (music horn), 2-way technology

- 100 V line technique
- Weatherproof and IP66 certified
- Wideband sound with a distinct bass volume
- 13 cm bass-midrange speaker and 25 mm (1") horn
- Suitable for indoor and outdoor applications
- Robust plastic housing of very low resonance

- Supplied with stainless steel mounting bracket
- 4 power taps, connection via screw terminals


TECHNICAL SPECIFICATIONS

IT-100TW


Impedance	-
Operating voltage	100V
Power rating	30/15/7.5/3.75 W
Peak music power output	-
Frequency range	110-16000Hz
Sensitivity	99dB/W/m
Radiation angle, horizontal	110°
Radiation angle, vertical	60°
Material (housing/cabinet)	ABS
Protective class	IP66
Weather resistance	yes
Mounting facility	mounting bracket
Features	2-way
Replacement voice coil	-
Admiss. ambient temp.	-20 °C to +50 °C
Dimensions	310 x 215 x 330 mm
Weight	4,42kg

* **Important Notice:** The retail prices shown here are non-binding recommendations that retailers can charge their customers. They are not part of any specific offer or advertisement. These prices include all charges as well as VAT, but do not cover any additional delivery and shipping costs. Our latest price lists for the retail market include all applicable delivery and payment terms for retailers.

Frequency Response

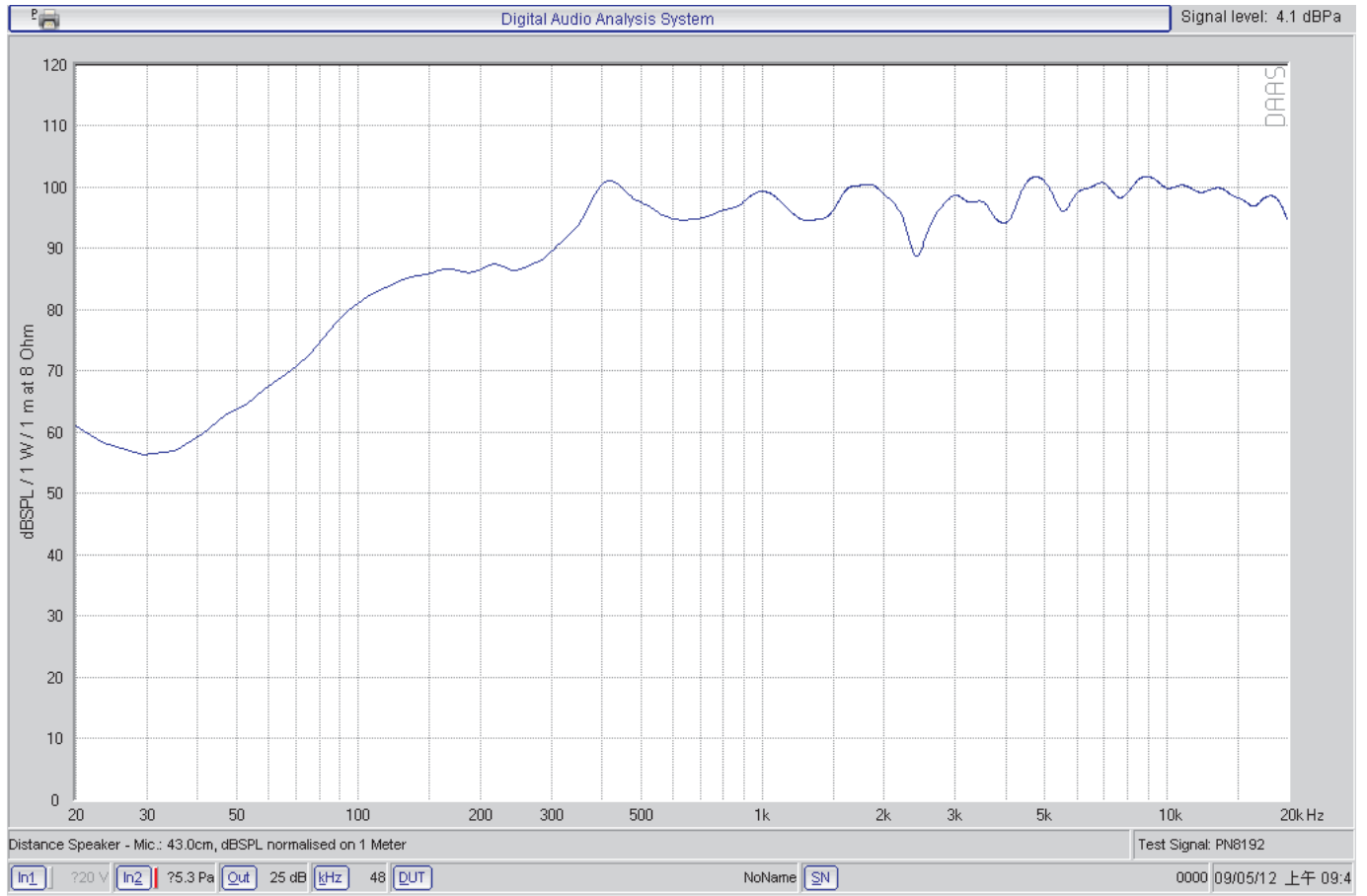

Polor Diagram /Horizontal

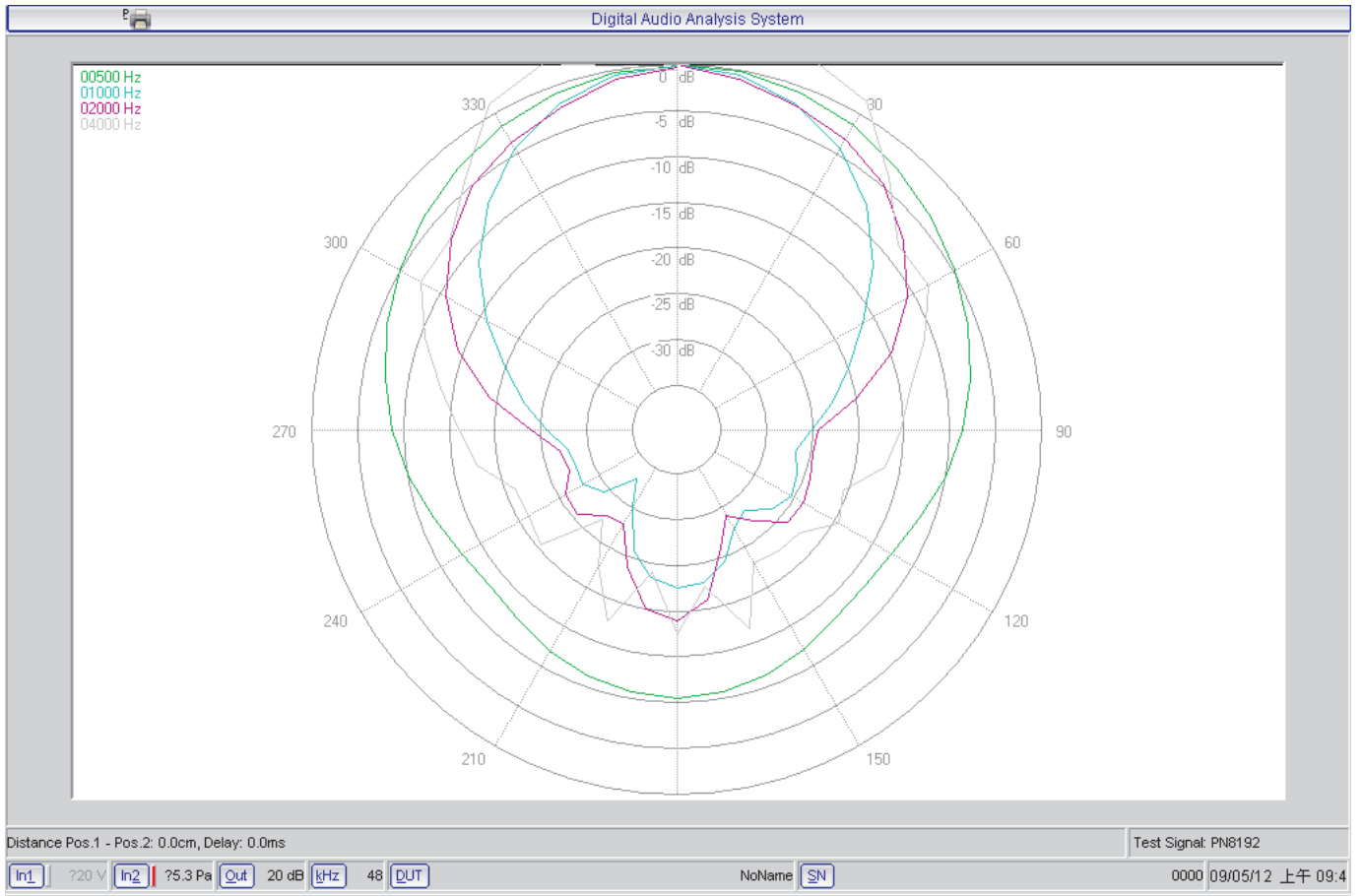

Polor Diagram /Vertical

