

**Industrial Ethernet
IE-BS-V01M-SCRJ-SM**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com



Bayonet plug-in connector sets according to IEC
61076-3-106 ver.1 (EtherNet/IP), RJ45 metal insert incl.
SC insert

General ordering data

Type	IE-BS-V01M-SCRJ-SM
Order No.	1221020000
Version	Flange FO, IP 67, Singlemode
GTIN (EAN)	4050118004113
Qty.	10 pc(s).

Datenblatt

**Industrial Ethernet
IE-BS-V01M-SCRJ-SM**

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technische Daten

Dimensions and weights

Net weight 66 g

Temperatures

Operating temperature -40 °C...+70 °C Storage temperature
 Installation temperature

General data

Colour	Miscellaneous	Connection 1	SCRJ
Connection 2	SCRJ	Fibre type	Singlemode
Housing main material	Zinc diecast	Insertion loss	≤ 0.5 dB
Plugging cycles	500	Protection degree	IP 67
Return loss (attenuation)	≥ 40 dB	Seal material	NBR

Standards

Connector standard IEC 61076-3-106 Var. 1,
 IEC 61754-24

Classifications

eClass 6.2 27-26-12-03 eClass 7.1 27-25-05-04

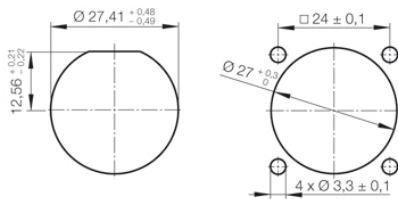
Approvals

Approvals



**Industrial Ethernet
IE-BS-V01M-SCRJ-SM**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Zeichnungen**Installation cut-out**

Mounting cut-out: 1. With central screw connection / 2. For mounting with four M3 screws