

**W-Series, Accessories**  
**WQB B/24****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16


D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

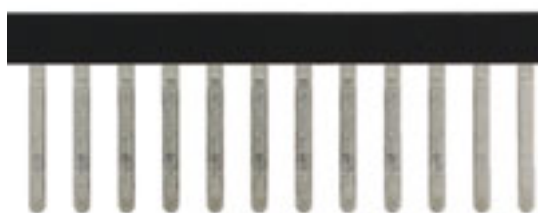

WQB B/24 157906



The versatile and extensive range of products - from 0.05 mm<sup>2</sup> to 300 mm<sup>2</sup> - means that you have diverse options for your applications at your disposal.

Hardened steel for mechanical strength and high-quality tinned copper for optimum conductivity. All materials comply with RoHS requirements and have been tested to current environment guidelines.

**General ordering data**

|            |                                                                             |
|------------|-----------------------------------------------------------------------------|
| Type       | WQB B/24                                                                    |
| Order No.  | <a href="#">1579060000</a>                                                  |
| Version    | W-Series, Accessories, Cross-connector, For the terminals, No. of poles: 24 |
| GTIN (EAN) | 4008190188597                                                               |
| Qty.       | 20 pc(s).                                                                   |

## W-Series, Accessories WQB B/24

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 14-0  
Fax: +49 5231 14-292083  
www.weidmueller.com

## Technische Daten

### Dimensions and weights

|        |         |            |           |
|--------|---------|------------|-----------|
| Length | 23.5 mm | Width      | 123.22 mm |
| Height | 2.5 mm  | Net weight | 8.13 g    |

### Temperatures

|                       |                     |
|-----------------------|---------------------|
| Operating temperature | Storage temperature |
|-----------------------|---------------------|

### Additional technical data

|                          |                   |                     |                 |
|--------------------------|-------------------|---------------------|-----------------|
| Explosion-tested version | No                | Installation advice | Direct mounting |
| Version                  | For the terminals |                     |                 |

### Rated data

|               |       |
|---------------|-------|
| Rated voltage | 800 V |
|---------------|-------|

### Material data

|          |        |        |       |
|----------|--------|--------|-------|
| Material | Copper | Colour | Black |
|----------|--------|--------|-------|

### System specifications

|                |                       |
|----------------|-----------------------|
| Product family | W-Series, Accessories |
|----------------|-----------------------|

### Classifications

|            |             |            |             |
|------------|-------------|------------|-------------|
| ETIM 3.0   | EC000489    | UNSPSC     | 30-21-18-01 |
| eClass 5.1 | 27-14-11-40 | eClass 6.2 | 27-14-11-40 |
| eClass 7.1 | 27-14-11-40 |            |             |

### Approvals

|      |         |
|------|---------|
| ROHS | Conform |
|------|---------|

### Downloads

|           |                                                   |
|-----------|---------------------------------------------------|
| DXF       | <a href="#">18599_WQB_B-24_DXF.dxf</a>            |
| STEP      | <a href="#">1579060000_18599_WQB_B-24_STP.stp</a> |
| 3D Modell |                                                   |