


**Z-series
ZDK 2.5/D/0**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

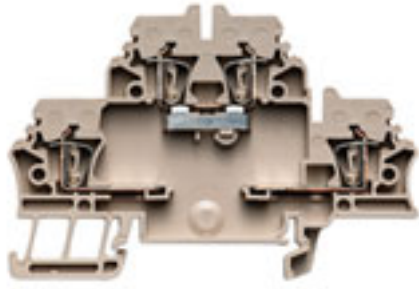

Modular terminals with diodes, LEDs, resistors and varistors solve a multitude of circuitry requirements. Electronic components can be integrated into the following versions:

General ordering data

Type	ZDK 2.5/D/0
Order No.	1714970000
Version	Z-series, Component terminal, Double-tier terminal, Rated cross-section:
GTIN (EAN)	4008190337292
Qty.	50 pc(s).

Z-series ZDK 2.5/D/0

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Technische Daten

Dimensions and weights

Height	53 mm	Height of lowest version	54 mm
Net weight	10.74 g		

Temperatures

Operating temperature		Storage temperature	
Continuous operating temp., min.	-50 °C	Continuous operating temp., max.	120 °C

Additional technical data

Version	Tension-clamp connection, with diode, for plug-in cross-connector, One end without connector
---------	---

Material data

Material	Wemid	UL 94 flammability rating	V-0
----------	-------	---------------------------	-----

System specifications

Product family	Z-series
----------------	----------

Classifications

ETIM 3.0	EC000897	eClass 6.2	27-14-11-20
eClass 7.1	27-14-11-20		

Approvals

Approvals



ROHS	Conform
------	---------