


ESG ESG 7/20 SIRIUS MC NE GE

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

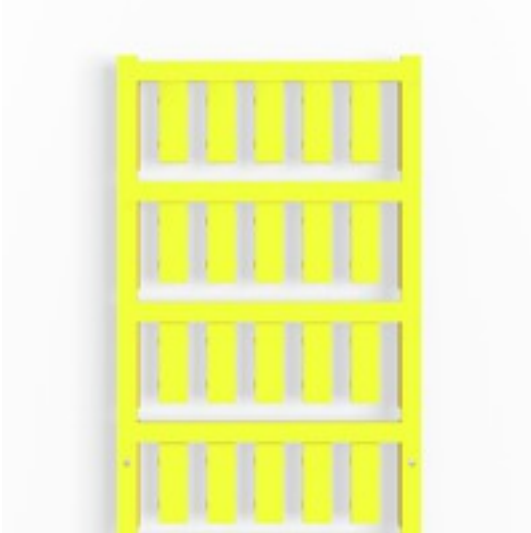

Similar to illustration



ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from the following manufacturers:

- Siemens
- Télémecanique
- ABB
- Beckhoff
- Lumberg
- Tags for all-purpose usage; self-adhesive or clip-on tags, depending on the type

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

Please note that these markers are not intended for printing with the SpeedMarking laser.

General ordering data

Type	ESG 7/20 SIRIUS MC NE GE
Order No.	1736181687
Version	ESG, Device markers x 20 mm, PA 66, Colour: yellow, pluggable
GTIN (EAN)	4032248208265
Qty.	200 pc(s).
compatible printer	1324380000

Creation date May 28, 2019 7:41:20 AM CEST

Data sheet

ESG ESG 7/20 SIRIUS MC NE GE

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technical data

Dimensions and weights

Width	20 mm	Width (inches)	0.787 inch
Height	7 mm	Height (inches)	0.276 inch
Depth	0.8 mm	Depth (inches)	0.031 inch
Net weight	0.51 g		

General data

Application/manufacturer	Siemens Sirius 3R	Colour	yellow
Halogen	No	Material	PA 66
Material colour according to resistance code	4	Number per sheet	40
Operating temperature range	-40...100 °C	UL 94 flammability rating	V-2
Version	pluggable	Width	20 mm

Classifications

ETIM 3.0	EC001288	ETIM 4.0	EC001288
ETIM 5.0	EC001288	ETIM 6.0	EC001288
UNSPSC	30-21-18-01	eClass 5.1	27-14-91-29
eClass 6.2	27-14-91-29	eClass 7.1	27-14-91-29
eClass 8.1	27-14-91-03	eClass 9.0	27-40-06-29
eClass 9.1	27-40-06-29		

Approvals

ROHS	Conform
------	---------

Downloads

Engineering Data	EPLAN, WSCAD
Engineering Data	STEP
Software	M-Print PRO configuration file

Data sheet

ESG
ESG 7/20 SIRIUS MC NE GE

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Drawings

