


**Z-series, WeiCoS
ZT 2.5/2AN/1**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

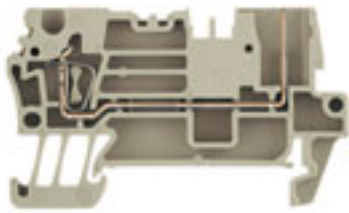

One terminal strip for the functional unit, one plug-in connector for the cable loom fabrication. All that remains to be done is to clip the two units together during final assembly – just like a plug-in connector. Finished! Whether for railway engineering, mechanical engineering or shipbuilding applications, all are served excellently by the products of the Weidmüller Z-Series. This is because the products are easy to use and practical, and the connections are simple, reliable and quick. Modular and flexible connection systems are especially in demand where complete functional units have to be prefabricated or replaced.

General ordering data

Type	ZT 2.5/2AN/1
Order No.	1815070000
Version	Z-series, WeiCoS, Feed-through terminal, Rated cross-section: 2.5 mm², Tension clamp connection, Wemid, Dark Beige
GTIN (EAN)	4032248369980
Qty.	50 pc(s).

Z-series, WeiCoS ZT 2.5/2AN/1

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Technische Daten

Dimensions and weights

Length	58 mm	Width	5.1 mm
Height	34.5 mm	Height of lowest version	35 mm
Net weight	5.78 g		

Temperatures

Operating temperature		Storage temperature	
Continuous operating temp., min.	-50 °C	Continuous operating temp., max.	120 °C

Additional technical data

Explosion-tested version	No	Open sides	right
Type of mounting	Snap-on	Version	1 tension-clamp connection - 1 plug-in connection, pluggable

Clampable wires (additional connection)

Conductor cross-section, flexible plus plastic collar DIN 46228/1, further connection, min.	0.5 mm ²	Conductor cross-section, flexible plus plastic collar DIN 46228/1, further connection, max.	2.5 mm ²
---	---------------------	---	---------------------

Clampable wires (rated connection)

Type of connection	Tension clamp connection	Type of connection 2	Plug-in connection
Stripping length	10 mm	Blade size	0.6 x 3.5 mm
Connection direction	top	Clamping range, rated connection, min.	0.13 mm ²
Clamping range, rated connection, max.	4 mm ²	Gauge to IEC 60947-1	A2
Wire connection cross section, solid core, max. rated connection	0.5 mm ²	Wire connection cross section, solid core max. rated connection	4 mm ²
Wire connection cross section, finely stranded, max.	4 mm ²	Wire connection cross-section, finely stranded, min.	0.5 mm ²
Wire connection cross section, finely stranded with wire-end ferrules DIN 46228/1, rated connection, min.	0.5 mm ²	Wire connection cross section, finely stranded with wire-end ferrules DIN 46228/1, rated connection, max.	2.5 mm ²
Cross-section for connected conductor, finely stranded with wire-end ferrules and plastic collars DIN 46228/4, rated connection, min.	0.5 mm ²	Wire connection cross-section, finely stranded with wire-end ferrules and plastic collars DIN 46228/4, rated connection, max.	2.5 mm ²
Wire connection cross section AWG, min.	AWG 12	Wire connection cross section AWG, max.	AWG 26

Rated data

Rated cross-section	2.5 mm ²	Rated voltage	500 V
Rated impulse withstand voltage	6 kV	Rated current	24 A
Current at maximum wires	24 A	Standards	IEC 60947-7-1, IEC 61984
Pollution severity	3	Max. voltage of clamp support & pluggable system	690 V

**Z-series, WeiCoS
ZT 2.5/2AN/1****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

Technische Daten**UL ratings data**

Certificate No. (cURus)

E60693

Conductor size Factory wiring max.

(cURus) 12 AWG

Conductor size Factory wiring min.

(cURus) 26 AWG

Conductor size Field wiring max. (cURus)

12 AWG

Conductor size Field wiring min. (cURus) 26 AWG

Current size D (cURus) 5 A

Current size C (cURus)

20 A

Voltage size D (cURus) 600 V

Voltage size C (cURus)

300 V

Material data

Insulating material

Wemid

Material

Wemid

Colour

Dark Beige

UL 94 flammability rating

V-0

System specifications

Product family

Z-series, WeiCoS

Type of connection

Tension clamp connection

Type of connection 2

Plug-in connection

Connection direction

top

Number of levels

4

No. of clamping points per level

1

Levels cross-connected internally

No

Mounting rail

TS 35

End cover plate required

Yes

Classifications

ETIM 3.0

EC000897

UNSPSC

30-21-18-11

eClass 5.1

27-14-11-20

eClass 6.2

27-14-92-14

eClass 7.1

27-14-11-20

Product information

Descriptive text technical data

2.5 mm² flexible wires with wire-end ferrules are crimped with the Weidmüller PZ 6/5 crimping tool. UL & CSA
D = 600 V / 5 A**Approvals**

Approvals



ROHS

Conform

Downloads

STEP

[_ZT 2.5_2AN_1 1815070000.stp](#)[3D Modell](#)