

**Industrial Ethernet
IE-BH-V04P****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com



PushPull plug-in connector according to IEC
61076-3-106 ver.4 (IEC24702), plastic, empty housing

General ordering data

Type	IE-BH-V04P
Order No.	1963520000
Version	Empty enclosure, Flange-mounted housing, Variant 4 to IEC 61076-3-106, IP67
GTIN (EAN)	4032248645619
Qty.	10 pc(s).

Industrial Ethernet IE-BH-V04P

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Technical data

Dimensions and weights

Net weight	18.2 g
------------	--------

Temperatures

Operating temperature, max.	70 °C	Operating temperature, min.	-40 °C
Operating temperature	-40 °C...70 °C	Storage temperature	
Installation temperature			

General data

Colour	Miscellaneous	Housing main material	PA UL 94 V0
Plugging cycles	750	Protection degree	IP67
Seal material	NBR	Sheath diameter, max.	10 mm
Sheath diameter, min.	5 mm	Type of mounting	4 screws, Central nut

Standards

Connector standard	IEC 61076-3-106 Var. 4	Certificate no. (cULus)	E316369
--------------------	------------------------	-------------------------	---------

Classifications

ETIM 3.0	EC001121	ETIM 4.0	EC001121
ETIM 5.0	EC001121	ETIM 6.0	EC001031
UNSPSC	30-21-18-17	eClass 5.1	27-26-12-03
eClass 6.2	27-25-05-04	eClass 7.1	27-25-05-04
eClass 8.1	19-17-01-25	eClass 9.0	27-18-27-02
eClass 9.1	27-18-27-02		

Approvals

Approvals



ROHS	Conform
------	---------

Downloads


Approval/Certificate/Document of Conformity	GOST Approval DUXR.E316369
Brochure/Catalogue	CAT 9 IETH 15/16 EN MB FREECONTACT EN FL FIELDWIRING EN PI PROFINET CABLING EN
User Documentation	MAN IE GUIDE DE MAN IE GUIDE EN

Industrial Ethernet IE-BH-V04P

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Drawings

Installation cut-out

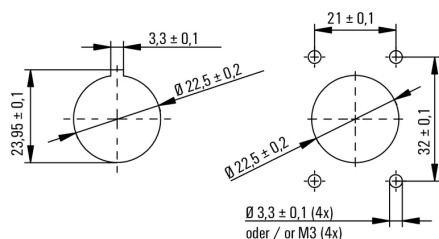

Mounting cut-out: 1. With central screw
connection / 2. For mounting with four M3 screws