

**RIDERSERIES RCL
RIM 4 24/60VUC GN**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Product image


Similar to illustration

Pluggable LEDs for the RIDERSERIES RCL relay base with optional protective functions

- With either green or red LED
- With free-wheel diode
- With protective varistor

General ordering data

| | |
|------------|---|
| Type | RIM 4 24/60VUC GN |
| Order No. | 8713790000 |
| Version | RIDERSERIES RCL, LED module, Protective varistor, Rated control voltage: 24...60 V UC, Plug-in connection |
| GTIN (EAN) | 4032248390168 |
| Qty. | 10 pc(s). |

Data sheet

**RIDERSERIES RCL
RIM 4 24/60VUC GN**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Technical data

Dimensions and weights

| | | | |
|------------|---------|-----------------|------------|
| Width | 12.5 mm | Width (inches) | 0.492 inch |
| Height | 9 mm | Height (inches) | 0.354 inch |
| Depth | 34.5 mm | Depth (inches) | 1.358 inch |
| Net weight | 3 g | | |

Temperatures

| | | | |
|-----------------------------|--|-----------------------------|----------------|
| Humidity | 40 °C / 93 % rel. humidity, no condensation | Operating temperature, max. | 70 °C |
| Operating temperature, min. | -40 °C | Storage temperature, max. | 70 °C |
| Storage temperature, min. | -40 °C | Operating temperature | -40 °C...70 °C |
| Storage temperature | -40 °C...70 °C | | |

Environmental Product Compliance

| | |
|------------|----------------|
| REACH SVHC | Lead 7439-92-1 |
|------------|----------------|

Rated data UL

| | |
|-------------------------|---------|
| Certificate No. (cURus) | E223759 |
|-------------------------|---------|

Input

| | | | |
|-----------------------|--------------|------------------|-----------|
| Rated control voltage | 24...60 V UC | Status indicator | Green LED |
| Protective circuit | Varistor | | |

General data

| | |
|--------|-------|
| Colour | black |
|--------|-------|

Further details of approvals / standards

| | | | |
|-----------|-------|-------------------------|---------|
| Standards | UL508 | Certificate No. (cURus) | E223759 |
|-----------|-------|-------------------------|---------|

Connection data

| | |
|------------------------|--------------------|
| Wire connection method | Plug-in connection |
|------------------------|--------------------|

Classifications

| | | | |
|------------|-------------|------------|-------------|
| ETIM 3.0 | EC000683 | ETIM 4.0 | EC000996 |
| ETIM 5.0 | EC002586 | ETIM 6.0 | EC002586 |
| UNSPSC | 32-11-15-03 | eClass 5.1 | 27-11-06-35 |
| eClass 6.2 | 27-11-06-35 | eClass 7.1 | 27-37-92-08 |
| eClass 8.1 | 27-37-92-08 | eClass 9.1 | 27-37-10-10 |

Approvals

Approvals



| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Data sheet

**RIDERSERIES RCL
RIM 4 24/60VUC GN**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

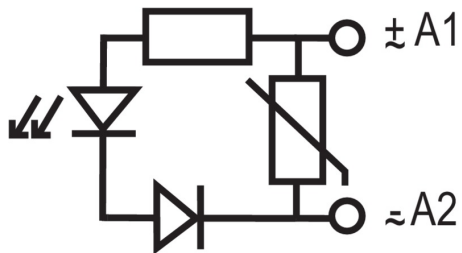
Technical data

Downloads

| | |
|------------------|------------------------------|
| Engineering Data | EPLAN, WSCAD |
| Engineering Data | STEP |

Data sheet**RIDERSERIES RCL
RIM 4 24/60VUC GN**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Drawings**Wiring diagram****Dimensional drawing**